

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201030001](#)
Status: **Active**
Overview: [PROFIBUS* Solutions](#)
Description: PROFIBUS* Attachable D-Sub Connector with Diagnostics LEDs and Programming Port, 90° Angle

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120103
IP Rating	IP67
Overview	PROFIBUS* Solutions
Product Name	D-Sub, Profibus*
Type	Field Attachable Connector
UPC	78678853530

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	Yes
Diagnostics Port	Yes
Gender	N/A
Keyway	None
Material - Connector Body	Die-Cast Zinc
Material - Contact	N/A
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Net Weight	90.000/g
Orientation	90° Angle
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

Electrical

Current - Maximum per Contact	4.0A
Voltage - Maximum	30V


Material Info

Old Part Number	PA9D01-42
-----------------	-----------

Reference - Drawing Numbers

Sales Drawing	SD-120103-003
---------------	---------------

*PROFIBUS is a trademark of PROFIBUS International

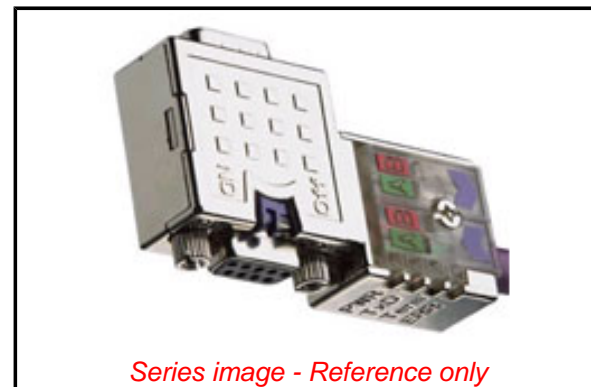

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

Search Parts in this Series

[120103 Series](#)