


Gecko Connectors

GECKO

Cable Connectors - Pre-Crimped Wires

- ❖ 4-finger Beryllium Copper contact on a female connector.
- ❖ Ready for assembling to housings on page 8.
- ❖ Crimp barrel meets all crimp guidelines and standards.
- ❖ 2A current capacity, resists high vibration and shock.
- ❖ Withstands extremes of temperature: -65°C to +150°C.

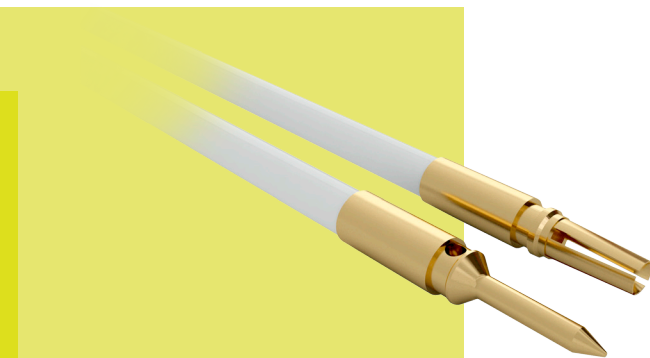

FEMALE SINGLE ENDED	FEMALE - FEMALE												
TOOLS													
<p>Contact Insertion/Removal Tool - Z125-902 See page 12</p> <p>❖ Instruction sheets available at www.harwin.com/instructions</p>													
HOW TO ORDER													
<p style="text-align: center;">G125 - F WX XXXX X 94</p> <table border="1" style="width: 100%;"> <tr> <td style="width: 25%;">SERIES CODE</td> <td style="width: 25%;">G125</td> <td style="width: 25%;">CABLE COLOUR</td> <td style="width: 25%;">94 White</td> </tr> <tr> <td>GENDER - FIRST END</td> <td>F Female</td> <td>TERMINATION - SECOND END</td> <td>L Loose cut end F Female</td> </tr> <tr> <td>CABLE SIZE</td> <td>W1 26 AWG W2 28 AWG W3 30 AWG W4 32 AWG</td> <td>CABLE LENGTH</td> <td>0150 150mm 0300 300mm (double-ended) 0450 450mm (single-ended) XXXX Special Order (length mm)</td> </tr> </table>		SERIES CODE	G125	CABLE COLOUR	94 White	GENDER - FIRST END	F Female	TERMINATION - SECOND END	L Loose cut end F Female	CABLE SIZE	W1 26 AWG W2 28 AWG W3 30 AWG W4 32 AWG	CABLE LENGTH	0150 150mm 0300 300mm (double-ended) 0450 450mm (single-ended) XXXX Special Order (length mm)
SERIES CODE	G125	CABLE COLOUR	94 White										
GENDER - FIRST END	F Female	TERMINATION - SECOND END	L Loose cut end F Female										
CABLE SIZE	W1 26 AWG W2 28 AWG W3 30 AWG W4 32 AWG	CABLE LENGTH	0150 150mm 0300 300mm (double-ended) 0450 450mm (single-ended) XXXX Special Order (length mm)										

All dimensions in mm.

Patent Published