

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1510140008](#)
Status: **Active**
Overview: [Milli-Grid™ Connector System](#)
Description: 2.00mm Pitch, Milli-Grid™ BMI Receptacle Housing, 8 Circuits, with Panel Mount Feature, Lead-Free

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-151014-0001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [151014](#)
 Application Panel-to-Board, Signal, Wire-to-Board
 Overview [Milli-Grid™ Connector System](#)
 Product Name Milli-Grid™ BMI
 UPC 887191588704

Physical

Circuits (maximum) 8
 Color - Resin Black
 Gender Receptacle
 Glow-Wire Compliant No
 Keying to Mating Part None
 Lock to Mating Part No
 Material - Resin PBT
 Net Weight 0.337/g
 Number of Rows 2
 Packaging Type Bag
 Panel Mount Yes
 Pitch - Mating Interface 2.00mm
 Pitch - Termination Interface 2.00mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating 0°C to +75°C

Electrical

Current - Maximum per Contact 2.0A


Solder Process Data

Lead-free Process Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-151014-0001
 Product Specification RPS-151013-0001
 Sales Drawing SD-151014-0001

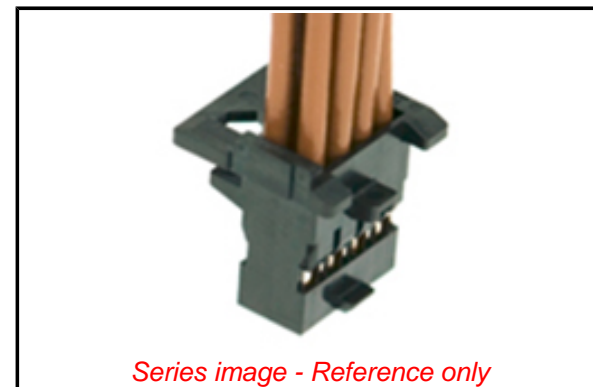

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/21/2016 (20 June
 2016)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

[151014 Series](#)

Mates With

Milli-Grid™ BMI Header [151013](#)

Use With

Milli-Grid™ Crimp Terminal [50394](#)