


Gecko Connectors

Cable Connectors - Pre-Crimped Wires

- Ready for assembling to housings on page 8.
- Crimp barrel meets all crimp guidelines and standards.
- 2A current capacity, resists high vibration and shock.
- Withstands extremes of temperature: -65°C to +150°C.

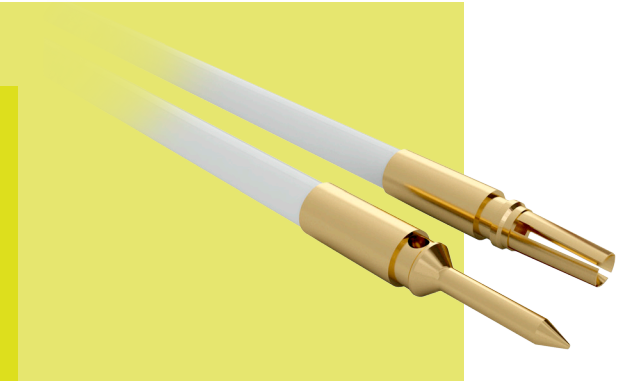

GECKO

MALE SINGLE ENDED	MALE - MALE
MALE - FEMALE	TOOLS
	<p>Contact Insertion/Removal Tool - Z125-902 See page 12</p> <p>➤ Instruction sheets available at www.harwin.com/instructions</p>

HOW TO ORDER

G125 - M WX XXXX X 94

SERIES CODE

GENDER - FIRST END	
M	Male

CABLE SIZE	
W1	26 AWG
W2	28 AWG
W3	30 AWG
W4	32 AWG

CABLE COLOUR	
94	White

TERMINATION - SECOND END	
L	Loose cut end
F	Female
M	Male

CABLE LENGTH	
0150	150mm
0300	300mm (double-ended)
0450	450mm (single-ended)
XXXX	Special Order (length mm)

All dimensions in mm.

Patent Published