


## Data Specification Sheet

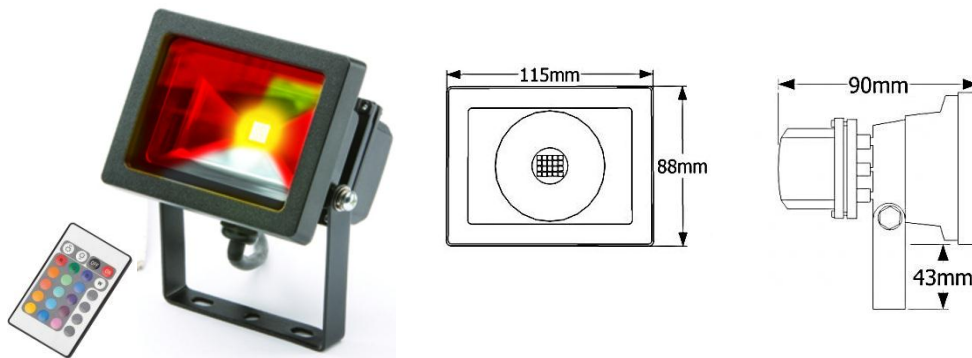

### FLE10RGBKB – RGB Colour Changing 10W LED Floodlight

|   |   |
|---|---|
| <b>ML Accessories Code</b>                | FLE10RGBKB  |
| <b>Description</b>                        | IP65 LED Colour Changing Floodlight                         |
| <b>Base Finishes available</b>            | Black   |
| <b>Overall dimensions (mm)</b>            | See above diagram   |
| <b>Weight</b>                             | 0.58KG  |
| <b>Fixing</b>                             | Stirrup Bracket   |
| <b>Typical location</b>                   | Indoor or Outdoor (Not suitable for food preparation areas) |
| <b>Lamp Supplied</b>                      | Yes non replaceable MCOB Samsung Multi-chip                 |
| <b>Lumen Output</b>                       | N/A   |
| <b>Lamp Life (Average)</b>                | 30,000 Hours  |
| <b>Lamp Colour</b>                        | RGB Colour Changing   |
| <b>Voltage (V)</b>                        | 220-230V 50Hz   |
| <b>Wattage (W)</b>                        | 10W   |
| <b>Circuit Watts</b>                      | 11W   |
| <b>Class</b>                              | Class I. Must be Earthed                                    |
| <b>IP</b>                                 | IP65  |
| <b>Photometric Testing</b>                | No  |
| <b>Instruction sheet</b>                  | Yes   |
| <b>Origin of manufacture</b>              | China   |
| <b>Pack Included</b>                      | Instructions  |
| <b>Main materials:</b>                    |   |
| • <b>Body</b>                             | Die-cast  |
| • <b>Reflector</b>                        | Aluminium   |
| • <b>Gasket</b>                           | Silicone Rubber   |
| • <b>Glass</b>                            | Toughened 3mm glass   |
| <b>Lamp holder cap and make</b>           | N/A   |
| <b>Lamp type</b>                          | MCOB RGB Samsung Multi-Chip                                 |
| <b>Electrical Connections</b>             | Pre-wired TRS Rubber 0.5m                                   |
| <b>Dimmable</b>                           | Yes   |
| <b>Distance from flammable object</b>     | N/A   |
| <b>Remote control supplied &amp; Type</b> | Yes. Infra-red 4mtr line of sight                           |
| <b>CE mark</b>                            | Yes   |
| <b>Quality Assurance System</b>           | Yes ISO 9001 QMS  |
| <b>Batch coding details</b>               | Yes   |
| <b>Certificate of Conformity</b>          | Yes   |
| <b>Manufactured in accordance</b>         | EN60 598-2-5  |
| <b>Guarantee Period</b>                   | 1 Year  |