

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0513470200](#)
Status: **Active**
Description: 3.30mm Pitch Wire-to-Wire Receptacle Housing, Positive Lock, Single Row, 2 Circuits, White

Documents:

[3D Model](#) [Product Specification PS-51284-002-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-51284-001-001 \(PDF\)](#)

General

Product Family Crimp Housings
 Series [51347](#)
 Application Signal, Wire-to-Wire
 Product Name N/A
 UPC 800756598970

Physical

Circuits (maximum) 2
 Color - Resin Natural
 Gender Female
 Glow-Wire Compliant No
 Lock to Mating Part Yes
 Material - Resin Nylon
 Net Weight 500.000/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 3.30mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -25°C to +85°C


Electrical

Current - Maximum per Contact 4.0A

Material Info

Reference - Drawing Numbers

Product Specification PS-51284-001-001, PS-51284-002-001
 Sales Drawing SD-51347-001, SD-51347-002

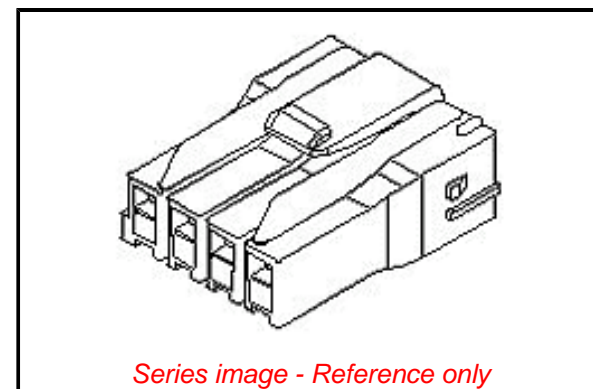

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
 ED/21/2016 (20 June
 2016)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[51347 Series](#)

Mates With

[51346-0200](#)

Use With

[51348](#) , [56187](#)