


Film, Metallized Polypropylene, Power, C4C, 0.047 uF, 5%, 1,200 V, 500 V, 70C

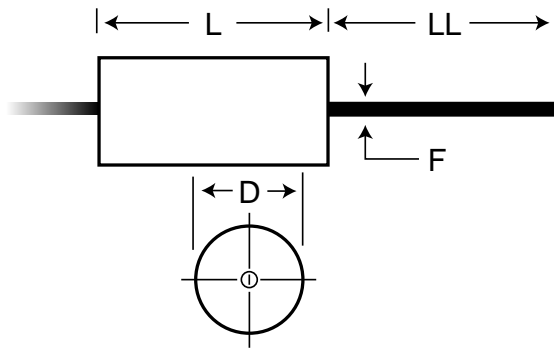

Dimensions	
D	10mm NOM
L	33mm NOM
LL	40mm +/-5mm

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	400

General Information	
Dielectric:	Metallized Polypropylene
Style:	Axial
Series:	C4C
RoHS:	Yes
Lead:	Wire Leads
Miscellaneous:	Polyester Tape & Resin Protection

Specifications	
Capacitance:	0.047 uF
Capacitance Tolerance:	5%
Voltage DC:	1200 VDC
Voltage AC:	500 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	700 V
Resistance:	27.1 mOhms (100kHz)
Current:	4 Amps (100kHz 70C), 33 Amps (Peak)