


Film, Metallized Polypropylene, Power, C4C, 0.47 uF, 5%, 1,200 V, 500 V, 70C

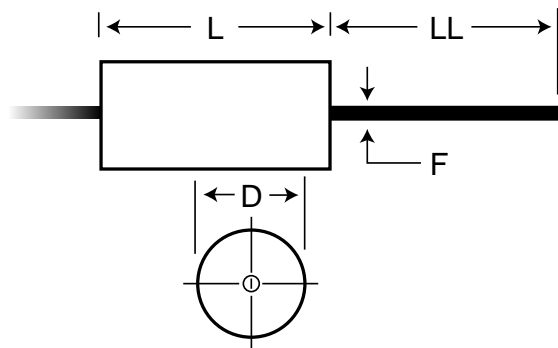

Dimensions

D	23mm NOM
L	44mm NOM
LL	40mm +/-5mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	70

General Information

Dielectric:	Metallized Polypropylene
Style:	Axial
Series:	C4C
RoHS:	Yes
Lead:	Wire Leads
Miscellaneous:	Polyester Tape & Resin Protection

Specifications

Capacitance:	0.47 uF
Capacitance Tolerance:	5%
Voltage DC:	1200 VDC
Voltage AC:	500 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	450 V
Resistance:	5.6 mOhms (100KHz)
Current:	9 Amps (100kHz 70C), 212 Amps (Peak)