


Film, Metallized Polypropylene, Power, C4C, 0.01 uF, 5%, 3,000 V, 750 V, 70C

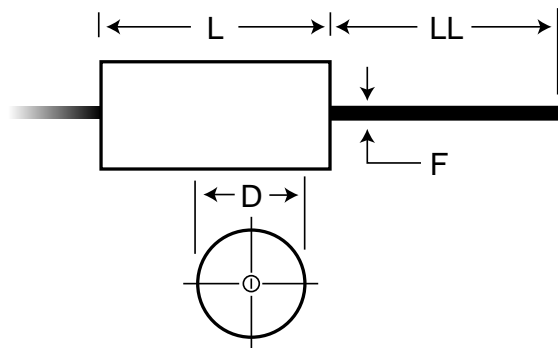

#### Dimensions

|    |             |
|----|-------------|
| D  | 12mm NOM    |
| L  | 33mm NOM    |
| LL | 40mm +/-5mm |

#### Packaging Specifications

|                     |      |
|---------------------|------|
| Packaging:          | Bulk |
| Packaging Quantity: | 300  |

#### General Information

|                |                                   |
|----------------|-----------------------------------|
| Dielectric:    | Metallized Polypropylene          |
| Style:         | Axial                             |
| Series:        | C4C                               |
| RoHS:          | Yes                               |
| Lead:          | Wire Leads                        |
| Miscellaneous: | Polyester Tape & Resin Protection |

#### Specifications

|                        |                                     |
|------------------------|-------------------------------------|
| Capacitance:           | 0.01 uF                             |
| Capacitance Tolerance: | 5%                                  |
| Voltage DC:            | 3000 VDC                            |
| Voltage AC:            | 750 VAC                             |
| Temperature Range:     | -40/+85C                            |
| Rated Temperature:     | 70C                                 |
| Dissipation Factor:    | 0.05%                               |
| Max dVdt:              | 2,100 V                             |
| Resistance:            | 90.3 mOhms (100kHz)                 |
| Current:               | 3 Amps (100kHz 70C), 21 Amps (Peak) |