


Joker Ratcheting combination wrenches, # 10

Ratcheting combination wrenches

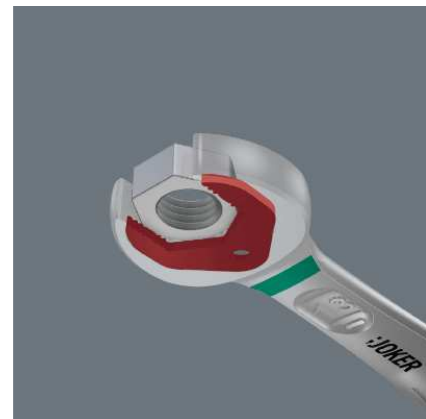

| | | | |
|-------------|---------------|---------------------|--------------|
| EAN | 4013288164360 | Dimension: | 240x50x22 mm |
| Code: | 05073270001 | Weight: | 85,12 g |
| Article-No. | | Country of origin: | CZ |
| | | Customs tariff no.: | 82041100 |

- Practical holding function thanks to the metal plate in the jaw
- Limit stop prevents any slipping
- The double-hex geometry reduces the risk of slipping
- Return angle of only 30°
- Take it easy Tool Finder: colour coding according to profile and size

High quality combination ratchet wrench by Wera. Everything that a wrench has to be able to do. And a whole lot more. Faster, better, stylish. Yes, a real Joker. The new generation of combination ratchet wrenches. Suitable for hexagon socket screws, bolts or nuts. Comes with holding function, thanks to the metal plate in the jaw, which reduces the risk of dropping nuts and bolts. The replaceable metal plate in the jaw secures nuts and bolts with its extra hard teeth and reduces the danger of slipping. The integrated limit stop prevents any slipping around the bolt head and allows higher torque to be applied. The double-hex geometry makes for a positive connection with nuts or bolts and reduces the risk of slipping. A return angle of only 30° at the open end prevents any time consuming flipping of the wrench. The ratchet mechanism at the ring end, with an exceptional, fine-tooth mechanism - 80 teeth in all - enables flexibility even in very confined working spaces. The specially forged geometry ensures high torque transfer and strength. The ratchet is manufactured out of high performance chrome molybdenum steel with nickel-chrome coating for high corrosion protection. "Take it easy" Tool Finder with colour coding according to sizes.