


KEMET Part Number: 050MD26AAMA1STD
(A901GF050V260A)

Aluminum Electrolytic, Motor Start, MD/A901, 50 uF, -0/+25%, -20/+70C

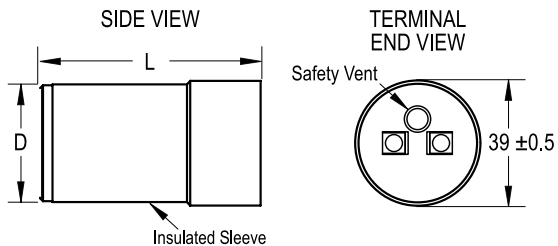

Dimensions	
D	38mm +/-0.5mm
L	75mm MAX

Packaging Specifications	
Packaging:	Bulk

General Information	
Dielectric:	Aluminum Electrolytic
Series:	MD/A901
Description:	Motor Start Aluminum Electrolytic
RoHS:	Yes
Lead:	Quick Connect

Specifications	
Capacitance:	50 uF
Capacitance Tolerance:	-0/+25%
Voltage AC:	260 VAC
Temperature Range:	-20/+70C
Rated Temperature:	70C
Life:	500 Hrs