

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0738380003**
Status: **Active**
Overview: SL™ Modular Connectors
Description: 2.54mm SL™ Crimp Housing, Single Row, Version N, TPA™ with Positive Latch, 3 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-70873-0540 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73838-005-001 \(PDF\)](#)

General

| | |
|----------------|--|
| Product Family | Crimp Housings |
| Series | 73838 |
| Application | Signal, Wire-to-Board, Wire-to-Wire |
| Comments | Terminal Position Assurance (TPA™) Piece |
| Overview | SL™ Modular Connectors |
| Product Name | SL™ |
| UPC | 800753951587 |

Physical

| | |
|-------------------------------|-----------------|
| Circuits (maximum) | 3 |
| Color - Resin | Natural |
| Gender | Receptacle |
| Glow-Wire Compliant | No |
| Material - Resin | Polyester Alloy |
| Net Weight | 0.068/g |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 2.54mm |
| Stackable | No |
| Temperature Range - Operating | -40°C to +105°C |


Solder Process Data

| | |
|------------------------------|-----|
| Lead-free Process Capability | N/A |
|------------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|------------------|
| Packaging Specification | PK-70873-0540 |
| Product Specification | PS-73838-005-001 |
| Sales Drawing | SD-73838-004 |

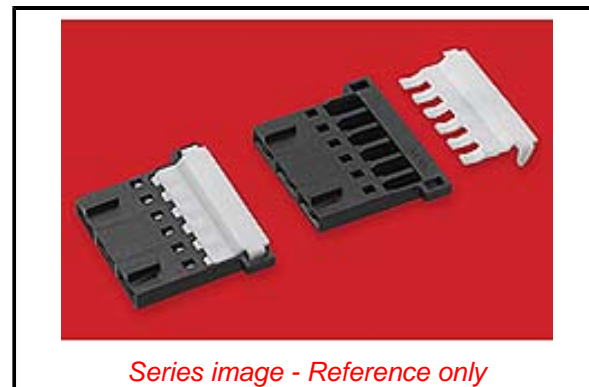

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | Green Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[73838](#) Series

Mates With

[70018](#) , [70543](#) , [70545](#) , [70553](#) , [70555](#) ,
[70107](#) Version A, [70107](#) Version B

Use With

[70058](#) , [71851](#) , [73838](#)