




Produktname | *Product name*: X20
 Artikelnummer | *Part Number*: 1600-0154
 Anfragenummer | *Inquiry Number*: AN2015332AA
 Ersteller / Datum | *Creator / Date*: LHE / 2016-08-19

| Version | Change | Date | Name |
|---------|--------|------------|------|
| | | | |
| | | | |
| | | | |
| | | | |
| | | | |
| V0 | --- | 2016-08-19 | LHE |

Leuchte / light

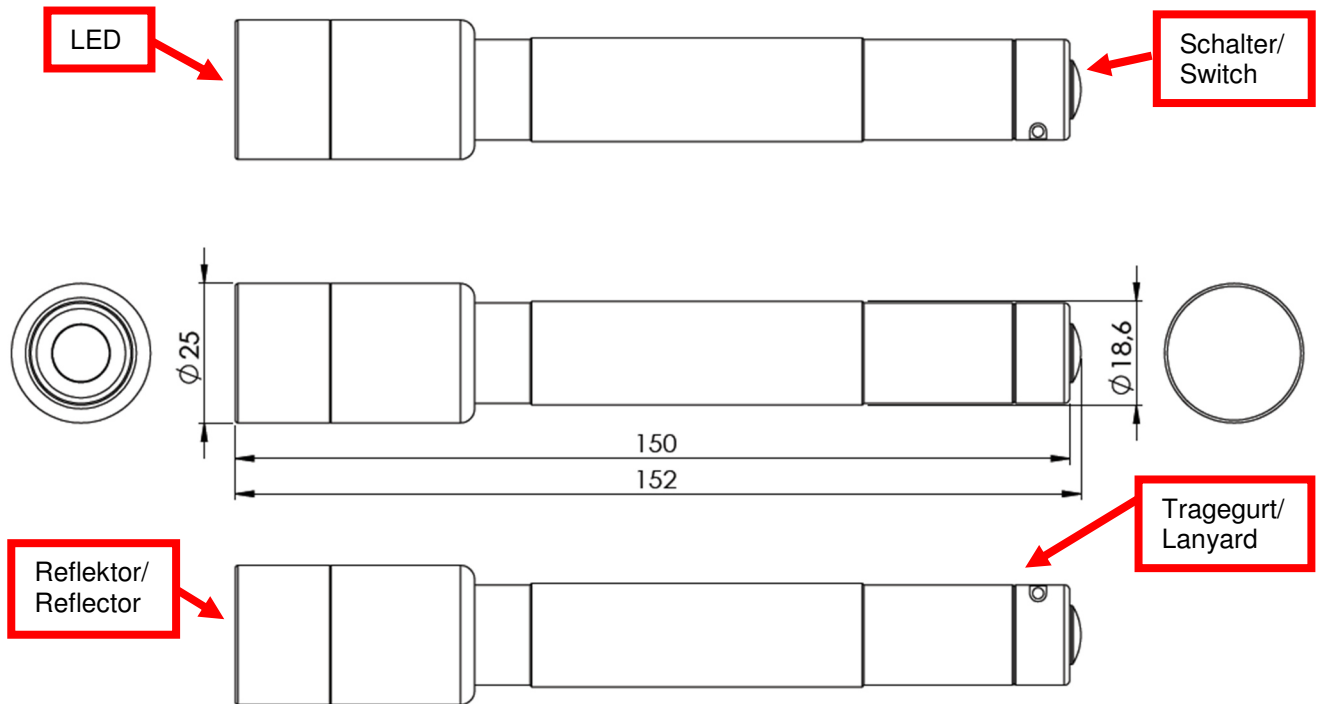

Technische Daten der Leuchte / technical data of the light:


| | | | |
|-------------------------|-----------------|----------------------|-----------------|
| Haupt-LED-Leuchtmittel: | 0.36W LED | Main LED illuminant: | 0.36W LED |
| Schalterfunktion: | 1. An 2. Aus | Switch function: | 1. On 2. Off |

| | | | |
|---|---------------------|--|----------------------|
| Lichtstrom: [Lumen] | 25lm | Luminous flux (light output): [Lumen] | 25lm |
| Leuchtdauer: | ca. 30h | Run time: | approx. 30h |
| Leuchtweite: | ca. 65m | Beam distance: | approx. 65m |
| Maximale Lichtstärke: [Candela] | 900cd | Peak beam / luminous intensity: [Candela] | 900cd |
| Maximale Beleuchtungsstärke: [Lux] | 900lx (Abstand: 1m) | Peak beam illuminance: [Lux] | 900lx (Distance: 1m) |
| Risikogruppe (EN 62471; Bewertet nach DIN IEC/TR 62778 Anhang C.2) | 2 | Risk group (EN 62471; Assessed with TR 62778 Annex C.2) | 2 |

| | | | |
|---|---|--|---|
| Benötigte Zellen: | 2x AA Mignon 1.5V Batterie/Batterien (Alkaline; LR6/AM3/MN1500) | Battery: | 2x AA Mignon 1.5V battery/batteries (Alkaline; LR6/AM3/MN1500) |
| Schutzart des Gehäuses: | IPx4 | Degree of protection by the enclosure: | IPx4 |
| Gehäusematerial: | Aluminium | Housing material: | Aluminium |
| Betriebstemperatur: | -10°C...25°C | Operating temperature: | -10°C...25°C |
| Lagertemperatur: | -10°C...50°C (Nur Alkaline Batterie/Batterien) -20°C...70°C (Nur Lampe) | Storage temperature: | -10°C...50°C (Alkaline battery/batteries only) -20°C...70°C (Torch only) |
| Empfohlene Lagerbedingungen: (Nur Alkaline Batterie/Batterien) | Temperatur: 5...25°C Luftfeuchtigkeit: 45...75% | Recommended storage conditions: (Alkaline battery/batteries only) | Temperature: 5...25°C Rel. humidity: 45...75 % |
| Approbationen: | CE | Approvals: | CE |
| Gewicht: | 65.5g nur die Lampe 110g mit 1 x Batterie (wie oben beschrieben) | Weight: | 65.5 only the torch 110g with 1 x battery (as described above) |
| Lieferumfang: | - 2 x Batterie (wie oben beschrieben) - Tragegurt | Shipment: | - 2 x battery (as described above) - Lanyard |
| Verpackung: | Blister-Verpackung | Package: | Blister shell |