


EMI Filters, Three Phase, FLLD4-TH, 530 VAC, 16 A, 120x115x80mm

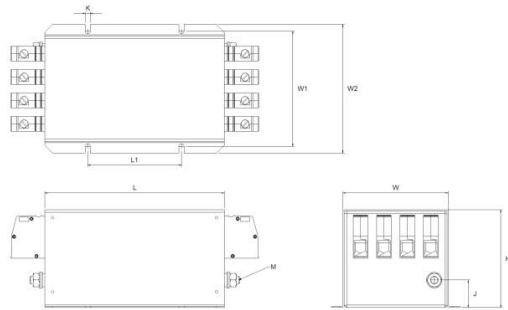

| Dimensions | |
|------------|-------------------|
| L | 120mm NOM |
| W | 115mm NOM |
| H | 80mm NOM |
| L1 | 80mm NOM |
| W1 | 127.5mm NOM |
| W2 | 143mm NOM |
| J | 32mm NOM |
| K | 6.5mm NOM |
| M (Earth) | Threaded Studs M6 |

| Packaging Specifications | |
|--------------------------|-------|
| Packaging: | Bulk |
| Packaging Quantity: | 1 |
| Weight: | 800 g |

| General Information | |
|---------------------|------------------------------------|
| Style: | Chassis Mount |
| Series: | FLLD4-TH |
| Description: | EMI Filter, Classis Mount, Compact |
| Features: | High Performance |
| RoHS: | Yes |

| Specifications | |
|---------------------------|-----------------|
| Voltage AC: | 530/305 VAC |
| Rated Frequency: | 50-60 Hz |
| Current: | 16 A (50C) |
| Rated Temperature: | 50C |
| Temperature Range: | -25/+100C |
| Climate Category: | 25/100/21 |
| Test Voltage DC (P to P): | 2250 VDC |
| Test Voltage DC (P to E): | 3000 VDC |
| Power Loss: | 6 W (25C 50 Hz) |
| Leakage Current: | 11 mA |