


EMI Filters, Three Phase, FLLD4-TH, 530 VAC, 36 A, 130x125x115mm

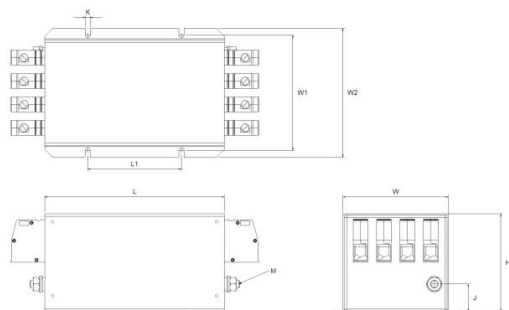

Dimensions	
L	130mm NOM
W	125mm NOM
H	115mm NOM
L1	90mm NOM
W1	137.5mm NOM
W2	153mm NOM
J	32mm NOM
K	6.5mm NOM
M (Earth)	Threaded Studs M6

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	1
Weight:	1.2 kg

General Information	
Style:	Chassis Mount
Series:	FLLD4-TH
Description:	EMI Filter, Chassis Mount, Compact
Features:	High Performance
RoHS:	Yes

Specifications	
Voltage AC:	530/305 VAC
Rated Frequency:	50-60 Hz
Current:	36 A (50C)
Rated Temperature:	50C
Temperature Range:	-25/+100C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Power Loss:	15 W (25C 50 Hz)
Leakage Current:	11 mA