


Aluminum Electrolytic, 105C, ALC40, 220 uF, 20%, 250 V, -40/+105C

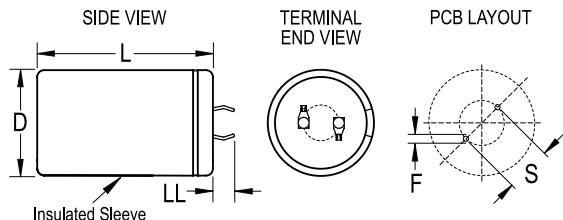

Dimensions	
D	25mm +1mm
L	30mm +/-2mm
S	10mm +/-0.1mm
LL	6.3mm +/-1mm
F	2mm +/-0.1mm

Packaging Specifications	
Weight:	28 g
Packaging:	Bulk

General Information	
Dielectric:	Aluminum Electrolytic
Series:	ALC40
Description:	Snap-In, Aluminum Electrolytic
RoHS:	Yes
Lead:	2 Pin

Specifications	
Capacitance:	220 uF
Capacitance Tolerance:	20%
Voltage DC:	250 VDC, 287.5 VDC (Surge)
Temperature Range:	-40/+105C
Rated Temperature:	105C
Life:	6000 Hrs (Rated Voltage And Ripple Current At 105C), 10000 Hrs (Rated Voltage At 105C)
Resistance:	592 mOhms (100Hz 20C), 405 mOhms (10kHz 20C)
Current:	0.93 Amps (100Hz 105C), 1.5 Amps (10kHz 105C)
Leakage Current:	165 uAmps (5min 20C)