


Film, Film/Foil Polypropylene, Motor Run, C276, 4 uF, 5%, 470 V

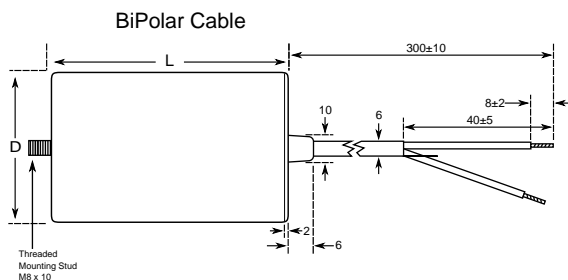

General Information

Dielectric:	Film/Foil Polypropylene
Style:	Can
Series:	C276
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
RoHS:	Yes
Termination:	Tin Copper
Lead:	BiPolar Cables
Approvals:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

Dimensions

D	25mm +1mm
L	58.5mm +/-2mm

Packaging Specifications

Mounting:	Bolt - M8x10
Packaging:	Bulk

Specifications

Capacitance:	4 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85C
Max dVdt:	15 V