


Film, Film/Foil Polypropylene, Motor Run, C276, 16 uF, 5%, 470 V

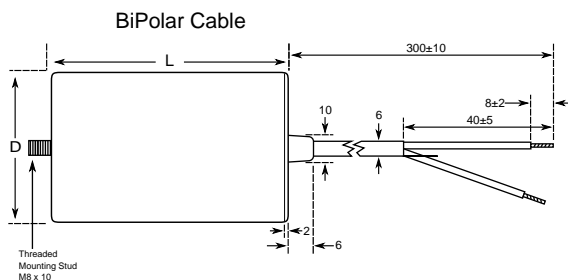

Dimensions	
D	35mm +1mm
L	71.5mm +/-2mm

Packaging Specifications	
Mounting:	Bolt - M8x10
Packaging:	Bulk

General Information	
Dielectric:	Film/Foil Polypropylene
Style:	Can
Series:	C276
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
RoHS:	Yes
Termination:	Tin Copper
Lead:	BiPolar Cables
Approvals:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

Specifications	
Capacitance:	16 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85C
Max dVdt:	15 V