


Film, Metallized Polypropylene, Power, C44A, 40 uF, 5%, 700 V, 400 V

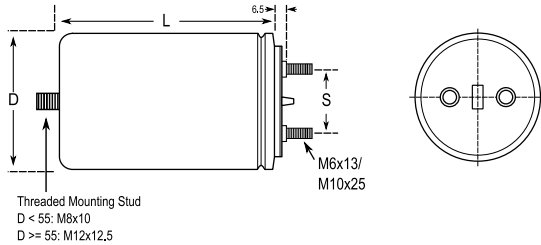

Dimensions

D	65mm +/-0.5mm
L	138mm +/-2mm
S	22.3mm +/-0.5mm

Packaging Specifications

Mounting:	Bolt - M12x12.5
Packaging:	Bulk
Packaging Quantity:	12

General Information

Dielectric:	Metallized Polypropylene
Style:	Can
Series:	C44A
RoHS:	Yes
Lead:	Threaded Studs M6
Miscellaneous:	Thermal Resistance = 4 C/W

Specifications

Capacitance:	40 uF
Capacitance Tolerance:	5%
Voltage DC:	700 VDC
Voltage AC:	400 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Max dVdt:	35 V
Resistance:	4 mOhms (TYP)
Current:	32 Amps, 1200 Amps (Peak)