


Film, Metallized Polypropylene, Power, C4AT, 20 uF, 5%, 250 V, 70C, Lead Spacing = 37.5mm

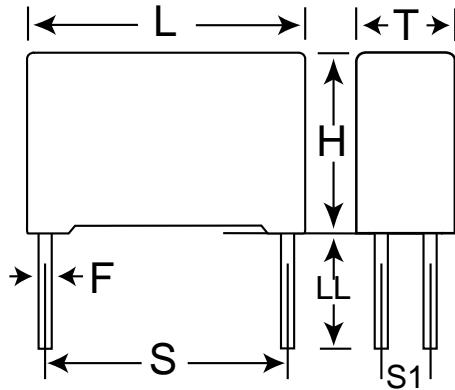

Dimensions

L	42.5mm NOM
H	37mm NOM
T	28mm NOM
S	37.5mm +/-0.4mm
S1	10.2mm +/-0.4mm
LL	6mm -2mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	36

General Information

Dielectric:	Metallized Polypropylene
Style:	Radial
Series:	C4AT
Features:	Switching
RoHS:	Yes
Lead:	4 Wire Leads

Specifications

Capacitance:	20 uF
Capacitance Tolerance:	5%
Voltage DC:	250 VDC
Voltage AC:	160 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	20 V
Resistance:	3.1 mOhms (100kHz)
Current:	22 Amps (100kHz 70C), 400 Amps (Peak)