


Film, Metallized Polypropylene, Power, C4AT, 15 uF, 5%, 450 V, 70C, Lead Spacing = 37.5mm

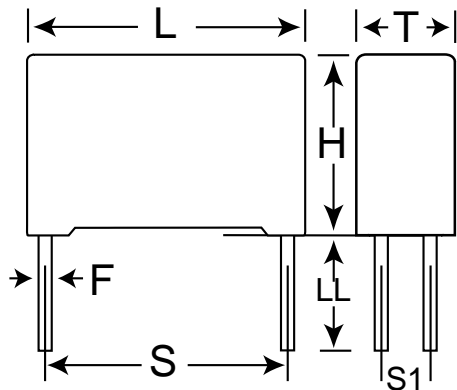

Dimensions

L	42mm NOM
H	45mm NOM
T	30mm NOM
S	37.5mm +/-0.4mm
S1	20.3mm +/-0.4mm
LL	6mm -2mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	36

General Information

Dielectric:	Metallized Polypropylene
Style:	Radial
Series:	C4AT
Features:	Switching
RoHS:	Yes
Lead:	4 Wire Leads

Specifications

Capacitance:	15 uF
Capacitance Tolerance:	5%
Voltage DC:	450 VDC
Voltage AC:	275 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	55 V
Resistance:	1.6 mOhms (100kHz)
Current:	29 Amps (100kHz 70C), 828 Amps (Peak)