


Film, Metallized Polypropylene, Power, C4AT, 5 uF, 5%, 600 V, 70C, Lead Spacing = 37.5mm

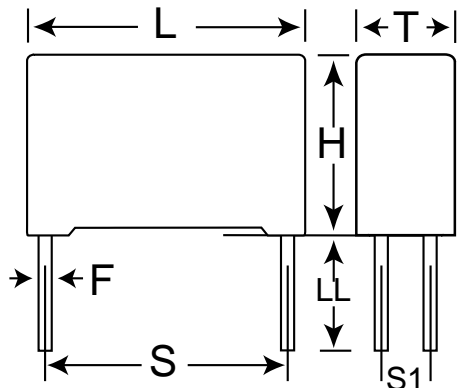

**Dimensions**

L	41.5mm NOM
H	40mm NOM
T	20mm NOM
S	37.5mm +/-0.4mm
S1	10.2mm +/-0.4mm
LL	6mm -2mm

**Packaging Specifications**

Packaging:	Bulk
Packaging Quantity:	58

**General Information**

Dielectric:	Metallized Polypropylene
Style:	Radial
Series:	C4AT
Features:	Switching
RoHS:	Yes
Lead:	4 Wire Leads

**Specifications**

Capacitance:	5 uF
Capacitance Tolerance:	5%
Voltage DC:	600 VDC
Voltage AC:	350 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	70 V
Resistance:	3.1 mOhms (100kHz)
Current:	22 Amps (100kHz 70C), 351 Amps (Peak)