


Film, Film/Foil Polypropylene, Motor Run, C878, 12 uF, 5%, 450 V

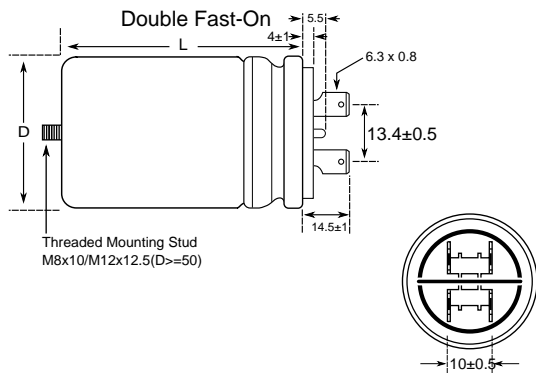

General Information	
Dielectric:	Film/Foil Polypropylene
Style:	Can
Series:	C878
Description:	Aluminum Case, Plastic Cover, Spun Seal
Features:	Spun Seal, Safety Class P2, UL_94 V0 Disk
RoHS:	Yes
Lead:	Fast On (2+2)
Approvals:	UL, VDE, CQC, CSA (240VAC), UL_94 V0 Disk

Dimensions	
D	35mm +1mm
L	78mm +/-2mm

Packaging Specifications	
Mounting:	Bolt - M8x10
Packaging:	Bulk

Specifications	
Capacitance:	12 uF
Capacitance Tolerance:	5%
Voltage AC:	450 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85C
Max dVdt:	20 V