


Film, Metallized Polypropylene, AC Filter, C9T, 68.5 uF, -5/+15%, 440 V

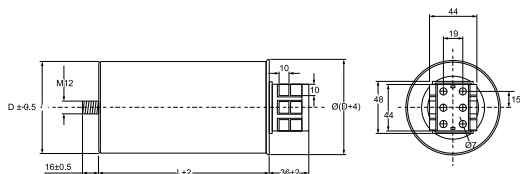

General Information

Dielectric:	Metallized Polypropylene
Style:	Can
Series:	C9T
Features:	Three Phase PFC
RoHS:	Yes
Lead:	Quick Connect
Approvals:	VDE
Miscellaneous:	Q = 12.5 kvar. Operating Freq. = 50 Hz

Dimensions

D	75mm +/-0.5mm
L	230mm +/-2mm

Packaging Specifications

Mounting:	Bolt - M12x16
Packaging:	Bulk
Packaging Quantity:	12

Specifications

Capacitance:	68.5 uF
Capacitance Tolerance:	-5/+15%
Voltage AC:	440 VAC
Temperature Range:	-25/+55C
Rated Temperature:	55C
Max dVdt:	30 V
Current:	21 Amps