


**KEMET Part Number: EFR(02)-240X240**  
 (UFSEFR020AT000, EFR(02)240x240)

Flex Suppressors, Commercial Grade, EFR

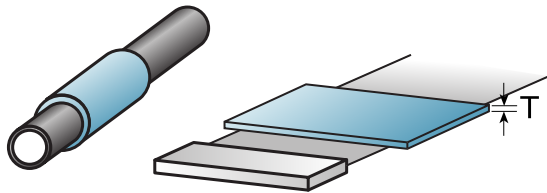

General Information	
<b>Style:</b>	Sheet
<b>Brand:</b>	TOKIN
<b>Series:</b>	EFR
<b>Description:</b>	Flex Suppressor Halogen Free Type
<b>Features:</b>	Standard Specifications
<b>RoHS:</b>	Yes
<b>Approvals:</b>	UL94 V-0, UL File No. E176124
<b>Environment:</b>	Halogen Free, PVC Free, Lead Free

Dimensions	
<b>Sheet Size</b>	240x240mm
<b>T</b>	0.2mm +/-0.05mm

Specifications	
<b>Temperature Range:</b>	-40/+105C
<b>Magnetic Permeability:</b>	60 TYP At 3MHz
<b>Effective Frequency:</b>	10 GHz MAX
<b>Resistance:</b>	1 MOhms MIN
<b>Specific Gravity:</b>	2.8 Atm TYP
<b>Conductivity:</b>	0.22 W/m K
<b>Tensile Strength:</b>	3.6 MPa MIN

Packaging Specifications	
<b>Tape Description:</b>	No Adhesive Tape