


KEMET Part Number: EFX(03)-240X240
 (UFSEFX030AT000, EFX(03)240x240)

Flex Suppressors, Commercial Grade, EFX

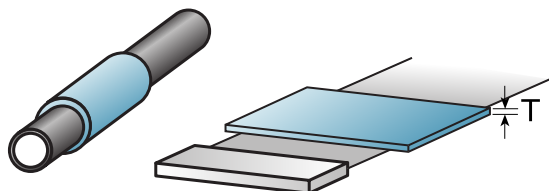

General Information	
Style:	Sheet
Brand:	TOKIN
Series:	EFX
Description:	Flex Suppressor Halogen Free Type
Features:	High Magnetic Permeability
RoHS:	Yes
Approvals:	UL94 HB, UL File No. E176124
Environment:	Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	240x240mm
T	0.3mm +0.1/-0.05mm

Packaging Specifications	
Tape Description:	No Adhesive Tape

Specifications	
Temperature Range:	-40/+105C
Magnetic Permeability:	100 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	0.1 MOhms MIN
Specific Gravity:	3.2 Atm TYP
Conductivity:	0.22 W/m K
Tensile Strength:	6.8 MPa MIN