


Supercapacitors, Radial Pin, Commercial Grade, FA, 0.22 F, -20/+80%, 11 V, Pin Leads, Lead Spacing = 15mm

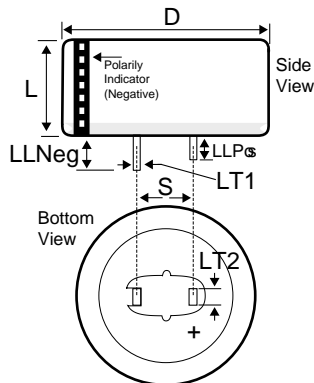

Dimensions	
D	36.5mm +/-0.5mm
L	27.5mm MAX
S	15mm +/-0.5mm
LL Negative	11.5mm MIN
LL Positive	9.5mm MIN

Packaging Specifications	
Lead:	Pin Leads
Packaging:	Bulk

General Information	
Series:	FA
Description:	Radial Cylindrical Double Layer Capacitor
RoHS:	Yes
Miscellaneous:	DischargeValue = 0.35 F

Specifications	
Capacitance:	0.22 F
Capacitance Tolerance:	-20/+80%
Voltage DC:	11 VDC
Temperature Range:	-25/+70C
Rated Temperature:	70C
Resistance:	6000 mOhms (1kHz)