


Film, Metallized Polypropylene, Safety, R47\_X2, 0.22 uF, 10%, 1,000 V, 520 V, 85C, Lead Spacing = 27.5mm

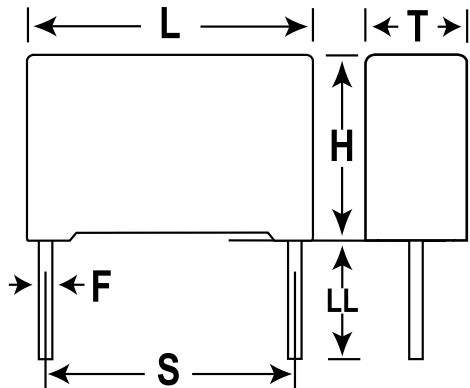

**Dimensions**

L	32mm +0.3mm
H	17mm +0.1mm
T	9mm +0.2mm
S	27.5mm +/-0.4mm
LL	25mm +2/-1mm
F	0.8mm +/-0.05mm

**Packaging Specifications**

Packaging:	Bulk
Packaging Quantity:	408

**General Information**

Dielectric:	Metallized Polypropylene
Style:	Radial
Series:	R47_X2
Features:	Pulse
RoHS:	Yes
Lead:	Wire Leads
Approvals:	ENEC, UL, cUL

**Specifications**

Capacitance:	0.22 uF
Capacitance Tolerance:	10%
Voltage DC:	1000 VDC
Voltage AC:	520 VAC
Temperature Range:	-40/+85C
Rated Temperature:	85C
Dissipation Factor:	0.1% 1kHz
Insulation Resistance:	100 GOhms
Max dVdt:	225 V
Safety Class:	X2