


**KEMET Part Number: SS11VL-04350**  
(UAL11VL0435000)

Commercial Grade, SS11VL, 0.035 H

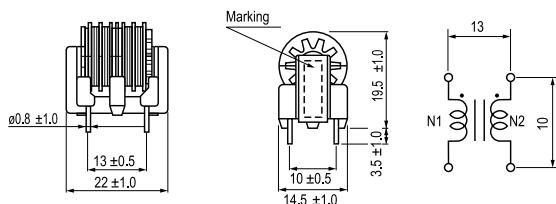

### General Information

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SS11VL
<b>Description:</b>	Common Mode Filter, Height: 20.5mm MAX
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530
<b>Notes:</b>	Lead Spacing (S/S1) Are For Reference Only.

### Dimensions

<b>L</b>	22mm +/-1mm
<b>T</b>	14.5mm +/-1mm
<b>H</b>	19.5mm +/-1mm
<b>S</b>	10mm MAX
<b>S1</b>	13mm NOM
<b>LL</b>	3.5mm +/-1mm
<b>F</b>	0.8mm NOM

### Specifications

<b>Inductance:</b>	35000 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	0.4 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	2.6 Ohms
<b>Insulation Resistance:</b>	100 MOhms

### Packaging Specifications

<b>Weight:</b>	10.7 g
----------------	--------