


**KEMET Part Number: SS20H-R06200**  
(UAL20HR0620000)

Commercial Grade, SS20H, 0.02 H

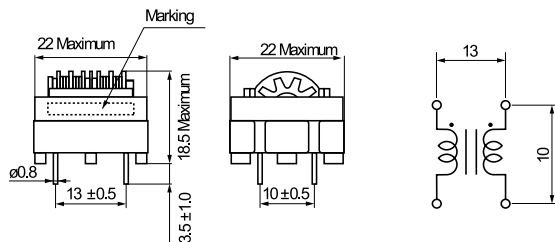

#### Dimensions

Dimension	Value
L	22mm MAX
T	22mm MAX
H	18.5mm MAX
S	10mm MAX
S1	13mm NOM
LL	3.5mm +/-1mm
F	0.8mm +/-0.1mm

#### Packaging Specifications

<b>Weight:</b>	12 g
----------------	------

#### General Information

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SS20H
<b>Description:</b>	Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530
<b>Notes:</b>	Lead Spacing (S/S1) Are For Reference Only.

#### Specifications

<b>Inductance:</b>	20000 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	0.6 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	930 mOhms
<b>Insulation Resistance:</b>	100 MOhms