 



**KEMET Part Number: SS35H-20170**  
(UAL35H20170000)

Commercial Grade, SS35V/35H, 0.017 H

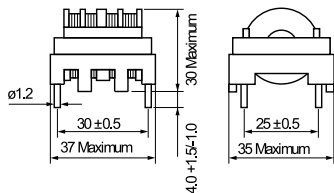

#### Dimensions

<b>L</b>	37mm MAX
<b>T</b>	35mm MAX
<b>H</b>	30mm MAX
<b>S</b>	25mm +/-0.5mm
<b>S1</b>	30mm +/-0.5mm
<b>LL</b>	4mm -1.5mm
<b>F</b>	1.2mm NOM

#### Packaging Specifications

<b>Weight:</b>	58 g
----------------	------

#### General Information

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SS35V/35H
<b>Description:</b>	Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530

#### Specifications

<b>Inductance:</b>	17000 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	2 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	280 mOhms
<b>Insulation Resistance:</b>	100 MOhms