


KEMET Part Number: SU10VD-20010
(UALSU10VD20010)

Commercial Grade, SU-10VD, 10 uH

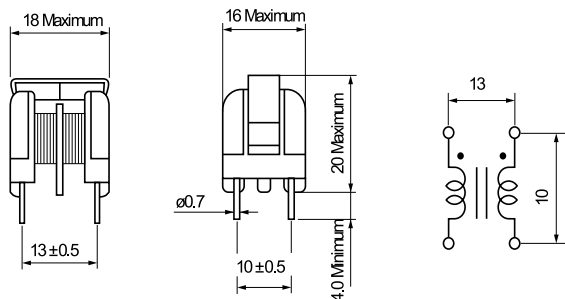

Dimensions

| Dimension | Value |
|-----------|---------------|
| L | 18mm MAX |
| T | 16mm MAX |
| H | 20mm MAX |
| S | 10mm +/-0.5mm |
| S1 | 13mm +/-0.5mm |
| LL | 4mm MIN |
| F | 0.7mm NOM |

Packaging Specifications

| | |
|----------------|-------|
| Weight: | 5.4 g |
|----------------|-------|

General Information

| | |
|-----------------------|---|
| Style: | Through-Hole Choke |
| Series: | SU-10VD |
| Description: | High Frequency Common Mode Filter |
| RoHS: | Yes |
| Miscellaneous: | Inductance Measurement Condition: 1kHz 1V KC530 |

Specifications

| | |
|-------------------------------|-----------|
| Inductance: | 10 uH |
| Rated Temperature: | 120C |
| Current: | 2 Amps |
| Voltage AC: | 250 VAC |
| DC Resistance: | 100 mOhms |
| Insulation Resistance: | 100 MOhms |