


**KEMET Part Number: SU9H-R02140**  
(UALSU9HR021400)

Commercial Grade, SU-9V-R/9H-R, 0.014 H

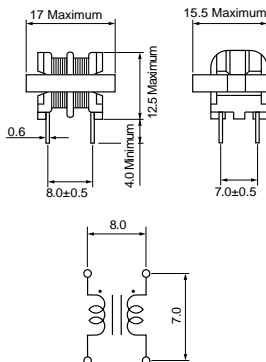

Dimensions	
L	17mm MAX
T	15.5mm MAX
H	12.5mm MAX
S	7mm +/-0.5mm
S1	8mm +/-0.5mm
LL	4mm MIN
F	0.6mm NOM

Packaging Specifications	
Weight:	3.2 g

General Information	
Style:	Through-Hole Choke
Series:	SU-9V-R/9H-R
Description:	Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530

Specifications	
Inductance:	14000 uH
Rated Temperature:	120C
Current:	0.2 Amps
Voltage AC:	250 VAC
DC Resistance:	6 Ohms
Insulation Resistance:	100 MOhms