

## RJ45 socket insert - VS-08-BU-RJ45-6-MOD/BU - 1653155


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



RJ45 socket insert, modular (Keystone), CAT6 (Link test), 8-position, shielded, socket on socket



### Key Commercial Data

Packing unit	5 STK
Minimum order quantity	5 STK
GTIN	 4 017918 970079
GTIN	4017918970079
Weight per Piece (excluding packing)	8.840 g
Custom tariff number	85366990
Country of origin	Taiwan

### Technical data

#### Mechanical characteristics

Number of positions	8
Number of slots	1
Shielded	yes
Insertion/withdrawal cycles	≥ 750
Connection method	Female
Degree of protection	IP20

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
---------------------------------	------------------

#### Material data

Flammability rating according to UL 94	V0
Contact carrier material	ABS
Contact material	Copper alloy
Contact surface material	Gold over nickel

# RJ45 socket insert - VS-08-BU-RJ45-6-MOD/BU - 1653155

## Technical data

### Electrical characteristics

Number of positions	8
Transmission characteristics (category)	CAT6 Link
Rated current	1.5 A
Degree of pollution	2
Rated voltage (III/3)	60 V

### Standards and Regulations

Flammability rating according to UL 94	V0
--	----

 
### Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings


Schematic diagram

Schematic diagram



Panel cutout

Dimensional drawing

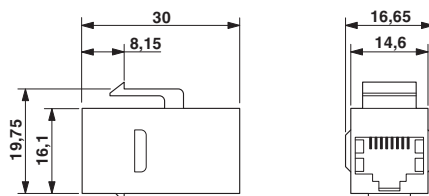

RJ45 socket insert, keystone

## Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260705
eCl@ss 7.0	27440309

# RJ45 socket insert - VS-08-BU-RJ45-6-MOD/BU - 1653155

## Classifications

### eCl@ss

eCl@ss 8.0	27440205
eCl@ss 9.0	27440205

### ETIM

ETIM 2.0	EC000438
ETIM 3.0	EC000438
ETIM 4.0	EC000438
ETIM 5.0	EC000438
ETIM 6.0	EC000438

### UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

## Approvals

### Approvals

---

### Approvals


### EAC

---

### Ex Approvals

---

### Approval details

EAC		B.01742
-----	---	---------

## Accessories

### Accessories

Panel mounting frame

## RJ45 socket insert - VS-08-BU-RJ45-6-MOD/BU - 1653155

### Accessories

Panel mounting frames - VS-08-A-RJ45/MOD-1-IP20 - 1689433



RJ45 panel mounting frame, 1x, IP20, for modular socket inserts (Keystone), without mounting screws

---

Panel mounting frames - VS-08-A-RJ45/MOD-1-R-IP67 - 1689844



RJ45 panel mounting frame, IP67, for modular socket inserts (Keystone), for round panel cutout, with grommet, with thread and union nut, color: gray

---

Panel mounting frames - VS-08-A-RJ45/MOD-1-IP67 - 1689080



RJ45 panel mounting frame, IP67, for modular socket inserts (Keystone), for square panel cutout, with grommet, without mounting screws, color: gray

---

Panel mounting frames - VS-08-A-RJ45/MOD-1-R-IP67 BK - 1658053



RJ45 panel mounting frame, IP67, for modular socket inserts (Keystone), for round panel cutout, with grommet, with thread and union nut, color: black

---

Panel mounting frames - VS-08-A-RJ45/MOD-1-IP67-BK - 1658642



RJ45 panel mounting frame, IP67, for modular socket inserts (Keystone), for square panel cutout, with grommet, without mounting screws, color: black

---

## RJ45 socket insert - VS-08-BU-RJ45-6-MOD/BU - 1653155

### Accessories

Panel mounting frames - VS-08-A-S-RJ45/MOD-1-R-IP67 - 1654772



RJ45 panel mounting frame, IP67, irradiated for welding applications, for modular socket inserts (Keystone), for round panel cutout, with grommet, with thread and union nut

---

Panel mounting frames - VS-08-A-S-RJ45/MOD-1-IP67 - 1652868



RJ45 panel mounting frame, IP67, irradiated for welding applications, for modular socket inserts (Keystone), for square panel cutout, with grommet, without mounting screws

---

---