


**KEMET Part Number: C410C220J2G5TA**  
(C410C220J2G5TABULK)

Ceramic, AxiMax, 22 pF, 5%, 200 V, COG, AxiMax, Commercial Standard

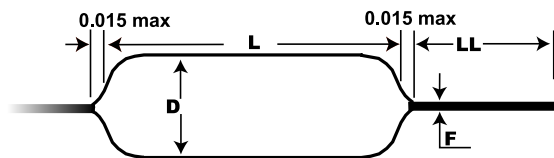

Dimensions	
D	2.31mm MAX
L	4.32mm MAX
LL	25.4mm +0.025/-0.076mm
F	0.51mm +0.025/-0.076mm

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	300

General Information	
Series:	AxiMax
Description:	AxiMax, Commercial Standard
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A

Specifications	
Capacitance:	22 pF
Capacitance Tolerance:	5%
Voltage DC:	200 VDC
Dielectric Withstanding Voltage:	500 V
Temperature Range:	-55/+125C
Temperature Coefficient:	COG
Dissipation Factor:	0.1%
Aging Rate:	0% Loss/Decade Hour
Insulation Resistance:	100 GOhms