


Tantalum, MnO2 Tantalum, Commercial Grade, T322, 150 uF, 10%, 6 V, 900 mOhms

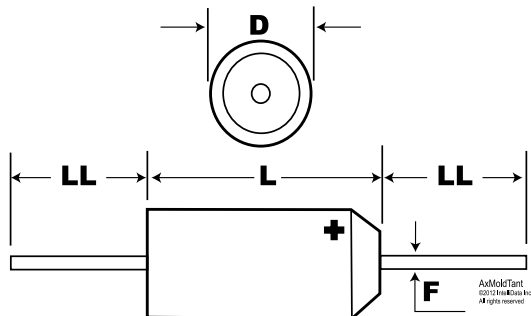

Dimensions

D	7.11mm MAX
L	13.46mm MAX
LL	38.1mm +/-6.35mm
F	0.64mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	100

General Information

Dielectric:	MnO2 Tantalum
Style:	Axial
Series:	T322
Description:	Axial, Solid Tantalum, Molded, Military (Non-ER), Low ESR
Features:	Low ESR
RoHS:	Yes
Termination:	Tin
Lead:	Wire Leads, Uninsulated

Specifications

Capacitance:	150 uF
Capacitance Tolerance:	10%
Voltage DC:	6 VDC (85C), 5 VDC (125C Surge), 0.06 V (125C Reverse)
Temperature Range:	-55/+125C
Rated Temperature:	85C
Resistance:	0.9 Ohms (100kHz)
Leakage Current:	5 uAmps (25C)