

# Screw plug - PROT-M12 MS-PA-CHAIN - 1430899

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



RoHS

## Key Commercial Data

Packing unit	5 STK
Minimum order quantity	5 STK
GTIN	 4 046356 332835
GTIN	4046356332835
Weight per Piece (excluding packing)	4.200 g
Custom tariff number	39269097
Country of origin	Germany

## Technical data

### Ambient conditions

Ambient temperature (operation)	-25 °C ... 85 °C
Degree of protection	IP65
	IP67

### Material

Flammability rating according to UL 94	V0
Material	PA 66 GF
Sealing material	NBR
Additional material specifications	PUR (Holding band)

### Standards and Regulations

Flammability rating according to UL 94	V0
--	----

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
------------	---

# Screw plug - PROT-M12 MS-PA-CHAIN - 1430899


## Technical data

### Environmental Product Compliance

	No hazardous substances above threshold values
--	--

## Drawings

Dimensional drawing

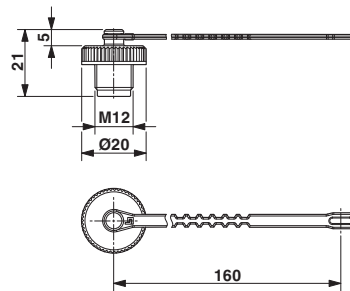

Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27149112
eCl@ss 7.0	27149112
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

### ETIM

ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002040
ETIM 6.0	EC000032

### UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31161501

## Screw plug - PROT-M12 MS-PA-CHAIN - 1430899

### Approvals

Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC		EAC-Zulassung
-----	---	---------------

---