


ZCKY53

limit switch lever ZCKY - metal round rod lever 3 mm L=125 mm - -40..120 °C

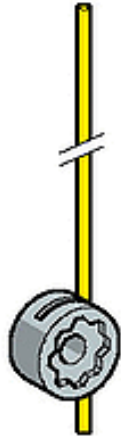

Main

Range of product	OsiSense XC
Series name	Standard format
Product or component type	Limit switch lever
Device short name	ZCKY
Product compatibility	XCKJ
Associated head	ZCKE05
Movement of operating head	Rotary
Type of operator	Rod lever spring return metal (round rod 3 mm, L = 125 mm)
Type of approach	Lateral approach

Complementary

Switch actuation	By any moving part
Positive opening	Without

Environment

Ambient air temperature for operation	10...120 °C for high temperature -40...70 °C for low temperature -25...70 °C for standard environment
Ambient air temperature for storage	-40...70 °C for low temperature 10...120 °C for high temperature -40...70 °C for standard environment
Environmental characteristic	High temperature Low temperature Standard environment

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0922 - Schneider Electric declaration of conformity

 [Schneider Electric declaration of conformity](#)

REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
-------	--

Product end of life instructions	Need no specific recycling operations
----------------------------------	---------------------------------------

[Contractual warranty](#)

Warranty period	18 months
-----------------	-----------
