


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **5040520298**
Status: **Active**
Overview: Pico-Lock™ Connector System
Description: 1.50mm Pitch Pico-Lock™ Crimp Terminal, Reel, AWG 30-32

Documents:

3D Model	Application Specification AS-504051-002-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-504052-001-001 (PDF)
Product Specification PS-504051-002-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-504051-001-001 (PDF)	

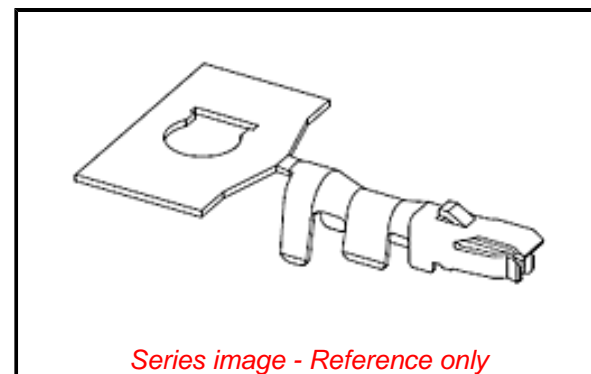

General

Product Family	Crimp Terminals
Series	504052
Application	Power, Signal
Crimp Quality Equipment	Yes
Overview	Pico-Lock™ Connector System
Product Name	Pico-Lock™
UPC	884982939943

Physical

Durability (mating cycles max)	30
Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Net Weight	0.265/g
Packaging Type	Reel
Wire Insulation Diameter	0.54 - 0.80mm
Wire Size AWG	30, 32
Wire Size mm²	N/A

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	150V

Material Info

Reference - Drawing Numbers

Application Specification	AS-504051-001-001, AS-504051-002-001
Crimp Specification	CS-504052-002-001
Packaging Specification	SPK-504052-001-001
Product Specification	PS-504051-002-001
Sales Drawing	SD-504052-002

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[504052](#) Series

Use With

[504051](#) 1.50mm Pitch Pico-Lock™ Crimp
Housing