

Ty-Rap® High-Performance Stainless Steel Cable Ties

Multiple barb lock design!



Ty-Rap® Multi-Lok Stainless Steel Self-Locking Cable Ties

Fire hazards — corrosive environments — temperature extremes — for many cable bundling applications, plastic ties are simply inadequate—or even dangerous.

That's why we developed stainless steel Multi-Lok Ties. Unaffected by fire, UV or extreme temperatures, corrosion-resistant Multi-Lok Ties provide a safe, strong, worry-free hold.

Quickly and easily applied by hand or with the Thomas & Betts Cable Tie Tensioner or Tensioning Hook, Multi-Lok Ties feature a unique, self-locking, multiple-locking system that holds in excess of 200 lbs.

Nylon II coating is halogen-free and non-toxic black. This weather-resistant coating is unaffected by UV sunlight. This adds resistance to corrosion, chemicals and weathering. Preferred stainless steel strap eliminates sharp edges.

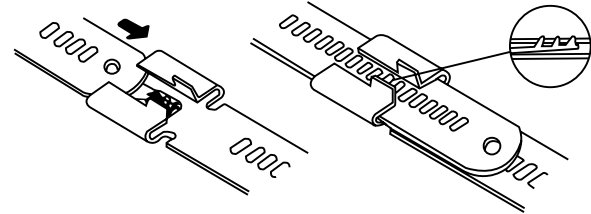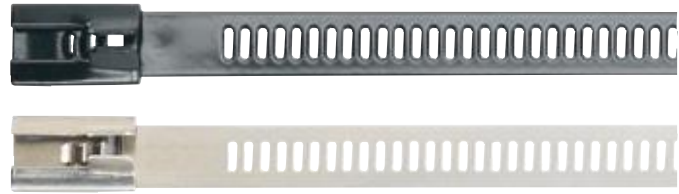

As the free end of the Multi-Lok tie passes through the buckle, three separate teeth (four teeth in the 12mm Multi-Lok) mesh with corresponding slots in the band automatically locking the tie as it is being tensioned. Self-locking Multi-Lok Ties feature an extremely strong, unique multiple locking system.



Type 316 Stainless Steel — Nylon 11 Halogen-Free Coated

| CAT. NO. | TENSILE STRENGTH | | WIDTH | | LENGTH | | WEIGHT | |
|-------------------|------------------|--|-------|----|--------|-----|--------|------|
| | LBS | | IN | MM | IN | MM | LBS | KG |
| TYS6-280C | 250 | | .276 | 7 | 6 | 150 | .66 | .30 |
| TYS9-280C | 250 | | .276 | 7 | 9 | 225 | .99 | .45 |
| TYS12-280C | 250 | | .276 | 7 | 12 | 300 | 1.32 | .60 |
| TYS18-280C | 250 | | .276 | 7 | 18 | 450 | 1.76 | .80 |
| TYS24-280C | 250 | | .276 | 7 | 24 | 610 | 2.64 | 1.20 |
| TYS6-470C | 250 | | .472 | 12 | 6 | 150 | 1.10 | .50 |
| TYS9-470C | 250 | | .472 | 12 | 9 | 225 | 1.65 | .75 |
| TYS12-470C | 250 | | .472 | 12 | 12 | 300 | 2.20 | 1.00 |
| TYS18-470C | 250 | | .472 | 12 | 18 | 450 | 2.97 | 1.35 |
| TYS24-470C | 250 | | .472 | 12 | 24 | 610 | 4.29 | 1.95 |

Packaging Quantity: 100/bag
.010" (.245mm) Thickness

Type 316 Stainless Steel — Uncoated

| CAT. NO. | TENSILE STRENGTH | | WIDTH | | LENGTH | | WEIGHT | |
|------------------|------------------|--|-------|----|--------|-----|--------|------|
| | LBS | | IN | MM | IN | MM | LBS | KG |
| TYS6-280 | 250 | | .276 | 7 | 6 | 150 | .66 | .30 |
| TYS9-280 | 250 | | .276 | 7 | 9 | 225 | .88 | .40 |
| TYS12-280 | 250 | | .276 | 7 | 12 | 300 | 1.21 | .55 |
| TYS18-280 | 250 | | .276 | 7 | 18 | 450 | 1.98 | .90 |
| TYS24-280 | 250 | | .276 | 7 | 24 | 610 | 2.64 | 1.20 |
| TYS6-470 | 250 | | .472 | 12 | 6 | 150 | 1.10 | .50 |
| TYS9-470 | 250 | | .472 | 12 | 9 | 225 | 1.65 | .75 |
| TYS12-470 | 250 | | .472 | 12 | 12 | 300 | 2.20 | 1.00 |
| TYS18-470 | 250 | | .472 | 12 | 18 | 450 | 3.19 | 1.45 |
| TYS24-470 | 250 | | .472 | 12 | 24 | 610 | 4.29 | 1.95 |

Packaging Quantity: 100/bag
.010" (.245mm) Thickness