

Pre-printed Cable Markers

Ovalgrip, slide on, straight cut

Ideally suited to panel building, mass transit, utilities, telecommunications and electrical contracting.

These markers are supplied continuous on a reel (HODS).

Markers are available as standard in yellow material marked in black and international resistor colour code. Characters are 0-9, A-Z and standard electrical symbols.

White material marked in black available on special request.


AT1 Arrowtags will fit 7 size 50 markers.

AT2 Arrowtags will fit 8 size 85 markers.

AT3 Arrowtags will fit 14 size 85 markers.


Features and Benefits

- Oval shaped markers designed to fit AT1, AT2 or AT3 (depends on Ovalgrip size)
- Ideal for use in maintenance and repair and fixed with cable ties
- Direct application to wire and cable before termination is also recommended
- Traditional wire marking available in yellow, white and colour code

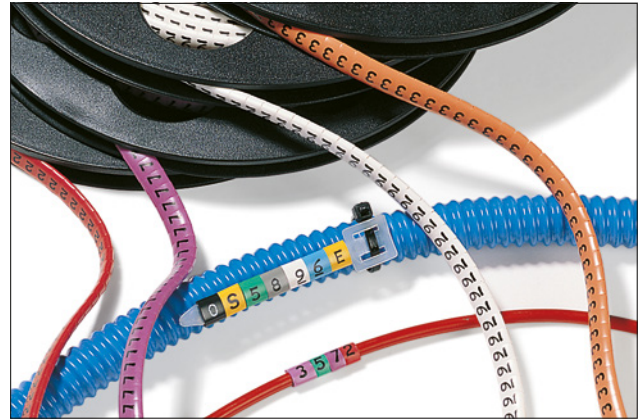

A simple idea for complex marking needs.

MATERIAL	Flexible Polyvinyl Chloride, cadmium free (PVC)
Operating Temperature	-65 °C to +105 °C, intermittent +135 °C
Flammability	UL94 V0 (3mm)
Specifications	BS-2782-540B, BS-6746C, IEC 304, IEC 757, UL224

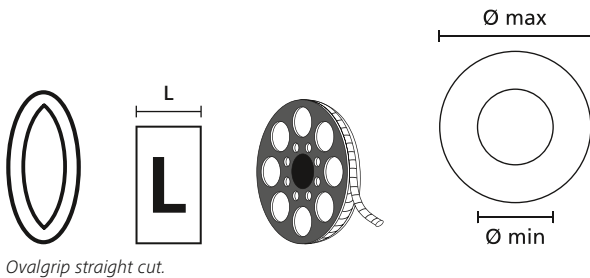

Ovalgrip straight cut.



For details on Arrowtags please see page 458.


TYPE	Bundle Ø min.	Bundle Ø max.	Length (L)	Pack Cont.	For Size
HODS50	1.7	3.6	4.0	1,000 pcs.	AT1
HODS85	1.8	6.3	4.5	1,000 pcs.	AT2/AT3

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



 For product specific approvals and specifications please refer to the Appendix.



Pre-printed Cable Markers


Ovalgrip, slide on, straight cut

HODS50	
Article-No.	
A	531-15014
B	531-15024
C	531-15034
D	531-15044
E	531-15054
F	531-15064
G	531-15074
H	531-15084
I	531-15094
J	531-15104
K	531-15114
L	531-15124
M	531-15134
N	531-15144
O	531-15154
P	531-15164
Q	531-15174
R	531-15184
S	531-15194
T	531-15204
U	531-15214
V	531-15224
W	531-15234
X	531-15244
Y	531-15254
Z	531-15264

HODS50	
Article-No.	
0	531-15274
1	531-15284
2	531-15294
3	531-15304
4	531-15314
5	531-15324
6	531-15334
7	531-15344
8	531-15354
9	531-15364
.	531-00174
/	531-00175
⊥	531-00176
+	531-00451
-	531-00452
0	531-15365
1	531-15366
2	531-15367
3	531-15368
4	531-15314
5	531-15370
6	531-15371
7	531-15372
8	531-15373
9	531-15374

HODS85	
Article-No.	
A	531-07935
B	531-07936
C	531-07937
D	531-07938
E	531-07939
F	531-07940
G	531-07941
H	531-07942
I	531-07943
J	531-07944
K	531-07945
L	531-07946
M	531-07947
N	531-07948
O	531-07949
P	531-07950
Q	531-07951
R	531-07952
S	531-07953
T	531-07954
U	531-07955
V	531-07956
W	531-07957
X	531-07958
Y	531-07959
Z	531-07960

HODS85	
Article-No.	
0	531-07925
1	531-07926
2	531-07927
3	531-07928
4	531-07732
5	531-07930
6	531-07931
7	531-07932
8	531-07933
9	531-07934
.	531-00384
/	531-07961
⊥	531-00386
+	531-07924
-	531-07923
0	531-07728
1	531-07729
2	531-07730
3	531-07731
4	531-07732
5	531-07733
6	531-07734
7	531-07735
8	531-07736
9	531-07737

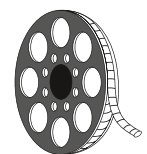

For product specific approvals and specifications please refer to the Appendix.