

73 06 160 T


KNIPEX X-Cut® Compact Diagonal Cutter with tether attachment point



- Compact and 25 % less weight. Powerful and precise
- Cuts finest strands as well as multi-core cables and piano wires
- Box-joint design: highest stability with low weight
- Doubly supported joint axis for heaviest duty
- High cutting performance with minimum effort due to optimum co-ordination of the cutting edge angle and transmission ratio
- 40% less force required compared with standard diagonal cutters of the same length
- Large opening width for thicker cables
- Cuts precisely, even through fine copper wires
- Compact, low-weight construction
- Universally usable, in the assembly, maintenance and production
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened
- Pliers with integrated, insulated tether attachment point for a tool tether

40% less force required compared with standard diagonal cutters of the same length
with double mounted hinged joint

Article No.	73 06 160 T
EAN	4003773081487
Pliers	chrome plated
Head	
Handles	
Insulation standard	IEC 60900 DIN EN 60900
Cutting capacities medium hard wire (diameter) Ø mm	3,8
Cutting capacities hard wire (diameter) Ø mm	2,7
Cutting capacity copper cable, multiple-stranded (diameter) Ø mm	12,0
Cutting capacities piano wire (diameter) Ø mm	2,2
Cutting capacities soft wire (diameter) Ø mm	4,8
Length mm	160
Net weight g	184

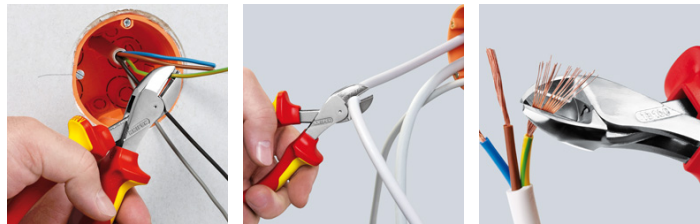

technical change and errors excepted