


# 78 03 140 ESD

## Electronic Super Knips® XL ESD



- For ultra fine cutting work, e.g. in electronics and fine mechanics
- Ground, very sharp cutting edges without bevel
- Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life
- Precision shaped tips cut wires resting on a board from 0.2 mm dia.
- Joint with stainless steel rivet
- Extremely smooth movement for minimum operator fatigue
- With opening spring and opening limiter
- Cutting edge hardness approx. 54 HRC
- INOX - stainless steel

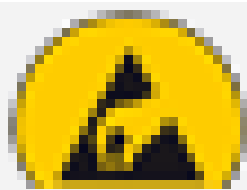


### ESD pliers (electrostatic discharge)

electrostatic energy is discharged through the handles in a gradual and controlled manner

which protects components endangered by electrostatic discharge

in accordance with applicable standards, e.g. IEC TR 61 340-5, DIN EN 61 340-5, SP Method 2472

<b>Article No.</b>	78 03 140 ESD
<b>EAN</b>	4003773081661
<b>Pliers</b>	
<b>Head</b>	polished
<b>Handles</b>	with multi-component grips
<b>Cutting capacities medium hard wire (diameter) Ø mm</b>	1,2
<b>Cutting capacities soft wire (diameter) Ø mm</b>	0,2 - 2,1
<b>B mm</b>	12,3
<b>D mm</b>	9,2
<b>A mm</b>	15,7
<b>Length mm</b>	140
<b>Net weight g</b>	77

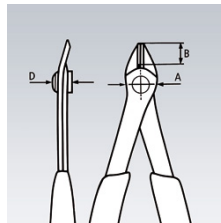

technical change and errors excepted