


78 61 140

Electronic *Super Knips*® XL



- For ultra fine cutting work, e.g. in electronics and fine mechanics
- In particular for cutting cable ties to length
- Ground, very sharp cutting edges without bevel
- Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life
- Precision shaped tips cut wires resting on a board from 0.2 mm dia.
- Joint with stainless steel rivet
- Extremely smooth movement for minimum operator fatigue
- With opening spring and opening limiter
- Cutting-edge hardness approx. 64 HRC
- Cutting edges additionally induction hardened
- Special tool steel, oil hardened in multiple stages

Article No.	78 61 140
EAN	4003773081685
Pliers	burnished
Handles	with multi-component grips
Head	
Cutting capacities medium hard wire (diameter) Ø mm	1,4
Cutting capacities soft wire (diameter) Ø mm	0,2 - 2,1
B mm	12,3
D mm	9,2
A mm	15,7
Length mm	140
Net weight g	77

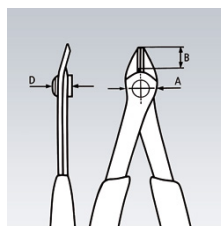

Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life

technical change and errors excepted