


EDL-150/WS - PA Loudspeaker

100V

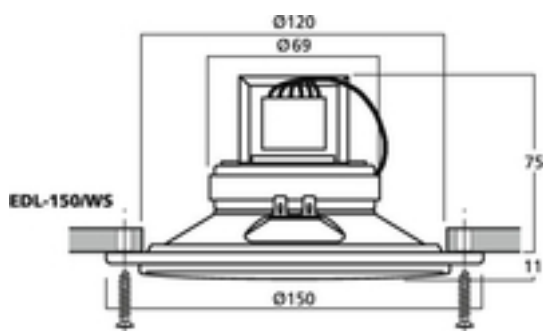

PA ceiling speaker

- 100 V line technique via audio transformer with 5 power taps
- Full range speaker with dual cone
- Metal housing with white, fixed protective metal grille



Technical Data

| | |
|--|-------------------------|
| Impedance (Z) | : - |
| Operating voltage | : 100 V |
| Frequency range | : 100-12,000 Hz |
| Resonant frequency (fs) | : - |
| Rec. crossov. frequ. (fmax.) (12 dB/oct.) | : - |
| Power rating | : 10/5/2.5/1.25/0.625 W |
| Peak music power output | : - |
| Sensitivity | : - |
| Max. rated SPL | : - |
| Max. voltage | : - |
| Radiation angle, horizontal | : - |
| Radiation angle, vertical | : - |
| Suspension compl. (Cms) | : - |
| Moving mass (Mms) | : - |
| Mech. Q factor (Qms) | : - |
| Electr. Q factor (Qes) | : - |
| Total Q factor (Qts) | : - |
| Equivalent volume (Vas) | : - |
| DC resistance (Re) | : - |
| Force factor (BxL) | : - |
| Voice coil induct. (Le) | : - |
| Voice coil diameter | : - |
| Voice coil former | : - |
| Linear excursion (X _{MAX}) | : - |
| Eff. cone area (Sd) | : - |
| Magnet weight | : - |
| Magnet diameter | : Ø 69 mm |
| Mounting cutout | : Ø 120 mm |
| Mounting depth | : 75 mm |
| Mounting hole diameter | : - |
| Hole spacing X-axis | : - |
| Hole spacing Y-axis | : - |
| Dimensions | : Ø 150 mm x 86 mm |
| Outside diameter | : Ø 150 mm |
| Width | : Ø 150 mm |



| | |
|-----------------------|--------------------|
| Height | : - |
| Depth | : 86 mm |
| Protective class | : - |
| Admiss. ambient temp. | : -20 °C to +55 °C |
| Weight | : 710 g |
| Sales unit | : 1 |
| Type of speaker | : 130 |