



Datenblatt - Fiche technique - Data sheet


11.04.5560



ROLINE GOLD HDMI High Speed Kabel, ST-ST, 15,0m


ROLINE GOLD Câble HDMI High Speed, M-M, 15 m

ROLINE GOLD HDMI High Speed Cable, M/M, 15 m

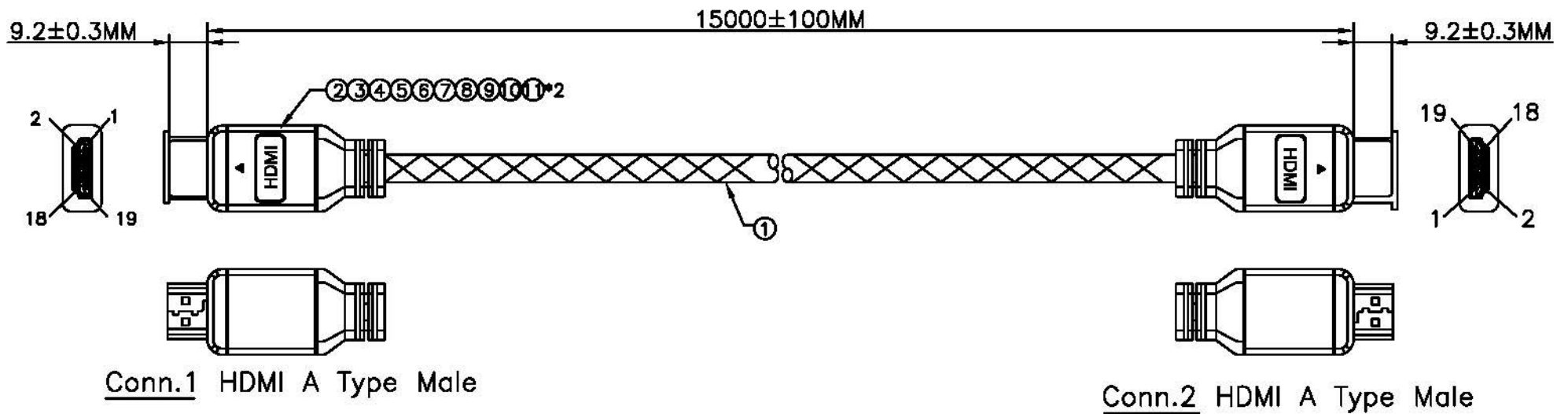

Electrical Test:

1. 100%Test(Open ,short ,miss wire)
2. Contact Resistance: 5 ohm max.
3. Insulation Resistance: 10M ohm min.
4. Hi-pot:300V DC/10ms

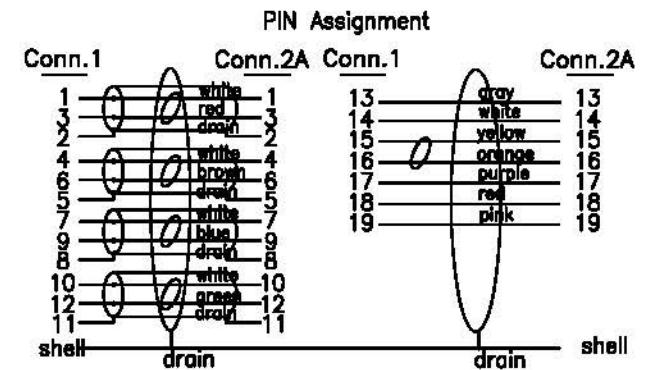

11	Wire Clip OD:8.0mm	2	pcs
10	TUBE BLACK #1.5mm THIN	0.032	m
9	HDMI 20# BALCK ABS JACKET	2	pcs
8	HDMI M TRANSPARENT DUST COVER	2	pcs
7	45P BLACK PVC	16	g
6	TRANSPARENT PE	3	g
5	TUBE BALCK #0.8mm THIN.	0.024	m
4	TUBE BALCK #2.0mm THIN.	0.08	m
3	HDMI 20# Shell aluminium alloy laser etching HDMI LOGO	2	pcs
2	HDMI M SOLDER TYPE,GOLD PLATED SHELL, BLACK INSULATION	2	pcs
1	UL20276 (26AWG*1P+EAM)*4C+26AWG*1P+26AWG*5C+AEB(50%AL)OD:8.0mm WITH BLACK/YELLOW NET	15	M
NO.	DESCRIPTION	Q'TY	UNIT

	TOLERANCE		
	INCHES	M/M	
		.X	.015
	.XX	.010	.10
	.XXX	.005	.05
DRAWN BY			
CHECK BY			
APPD BY			

rotronic

11.04.5560

ROLINE GOLD HDMI Cable, A M / A M
15m, black w/yellow & black nylon net

SCALE	NONE	DRAWING NO.:	REV. A
UNIT	MM		
DATE	2013.07.26		

1/1