


KEMET, OHD

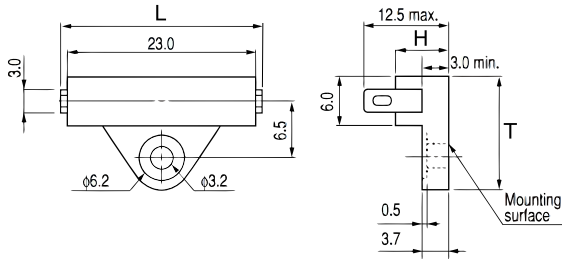

General Information	
Series:	OHD
Type:	Thermal Sensors
Style:	Radial Tab
Description:	Thermal Guard
Features:	Overheating Monitoring, Simple Circuit Design, Reliabile ON-OFF Operation, Compact, High Speed Response
Lead:	Tab Leads
RoHS:	Yes

Dimensions	
L	27mm MAX
H	6mm
T	13.5mm

Packaging Specifications	
Packaging:	Bulk, Tray
Packaging Quantity:	1000

Specifications	
Rated Temperature:	50C
Rated Temperature Tolerance:	+/-5C
Temperature Range:	+30/+130C
Voltage DC:	110 VDC MAX (Opening/Closing), 2500 VAC/1min Or 3000 VAC/1sec (Insulation Withstand Voltage, Between Terminals And Mounting Resin Surface)
Voltage AC:	110 VAC MAX (Opening/Closing)
Current:	0.3 Amps AC/DC MAX (Opening/Closing), 0.1 mAmps MIN (1VDC, Opening/Closing)
Resistance:	150 mOhms MAX (Contact Resistance)
Miscellaneous:	Differential Temperature = 10C MAX. Contact Shape M = Make. Power = 6W AC/DC MAX (Opening/Closing)