


Price\* : 93.00 GBP

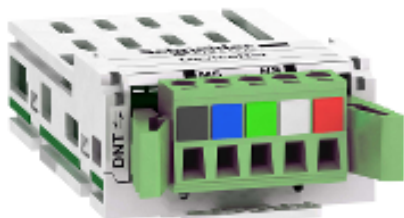

### Main

|                           |                      |
|---------------------------|----------------------|
| Range of product          | Altivar              |
| Product or component type | Communication module |

### Complementary

|                                |  |
|--------------------------------|--|
| Range compatibility            | Altivar Process ATV900<br>Altivar Process ATV600<br>Altivar Machine ATV340<br>Altivar 32<br>Altivar Machine ATV320   |
| Communication port protocol    | DeviceNet  |
| Electrical connection          | 1 connector 1 removable 5-way screw connector  |
| Transmission rate              | 125 kbps, 250 kbps and 500 kbps configurable   |
| Cable distance between devices | 100 m for 500 kbps<br>500 m for 125 kbps   |
| Addressing                     | 1...63 configurable by graphic terminal/SoMove software  |
| Communication service          | Inputs : polled, change of state, cyclic<br>Outputs : polled<br>ODVA AC drive and CiA 402 profile<br>Auto device replacement<br>Communication monitoring time out adjustable by DeviceNet configurator |
| Display type                   | 1 LED for MS (Module Status)<br>1 LED for NS (Network Status)  |
| Alarm function                 | Received instruction by graphic terminal<br>Control mode received by graphic terminal  |
| Bus profile                    | CIP AC Drive<br>CiA 402  |

### Offer Sustainability

|                          |   |
|--------------------------|---|
| Sustainable offer status | Not Green Premium product   |
| RoHS (date code: YYWW)   | Compliant - since 1020 - Schneider Electric declaration of conformity<br><a href="#">Schneider Electric declaration of conformity</a> |

Contractual warranty

---

|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

---