

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0503978000](#)  
**Status:** **Active**  
**Overview:** [CP Wire-to-Board and Wire-to-Wire Connector Systems](#)  
**Description:** 2.50mm and 3.30mm Pitch Crimp Terminal, Female, 22-28 AWG, Reel

**Documents:**

<a href="#">3D Model</a>	<a href="#">Application Specification 5056050000-A00 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification 5056050000-A01 (PDF)</a>
<a href="#">Product Specification 5056050000-000 (PDF)</a>	<a href="#">Application Specification AS-504693-001-001 (PDF)</a>
<a href="#">Product Specification PS-504693-001-001 (PDF)</a>	<a href="#">Application Specification AS-504693-002-001 (PDF)</a>
<a href="#">Product Specification PS-51111-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-51111-003 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

**General**

Product Family	Crimp Terminals
Series	<a href="#">50397</a>
Application	Signal
Crimp Quality Equipment	Yes
Overview	<a href="#">CP Wire-to-Board and Wire-to-Wire Connector Systems</a>
Packaging Alternative	<a href="#">50397-8100 (Loose)</a>
Product Literature Order No	987651-6581
Product Name	CP-3.3
UPC	800754317719

**Physical**

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	89.600/mg
Packaging Type	Reel
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.15-1.80mm
Wire Size AWG	22, 24, 26, 28
Wire Size mm <sup>2</sup>	N/A


**Electrical**

Current - Maximum per Contact	3.0A
Voltage - Maximum	300V AC (RMS)/DC

**Material Info**

**Reference - Drawing Numbers**

Application Specification	5056050000-A00, 5056050000-A01, AS-504693-001-001, AS-504693-002-001
Product Specification	5056050000-000, PS-504693-001-001, PS-51111-001, PS-51111-003
Sales Drawing	SD-50397-001

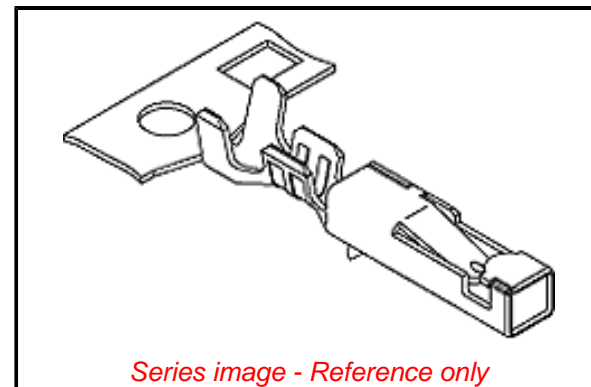

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[50397](#) Series

**Use With**

[51111](#) , [504693](#) , [505605](#)