



**PERFORMANCE FEATURES:**

- High visibility allows for easy stocking and retrieval
- Intermediate clip shelves make for easy bolt-free assembly and adjustment
- Shelves are adjustable on 1" increments
- Sway braces on side and back provide stability


Additional Shelves and Clips available, see **pgs. 94 & 100**.  
22 Gauge Shelving also available in three different sizes, see **pg.102**.

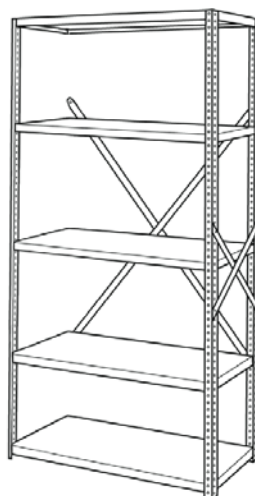

**5 SHELF  
ADD-ON KITS**

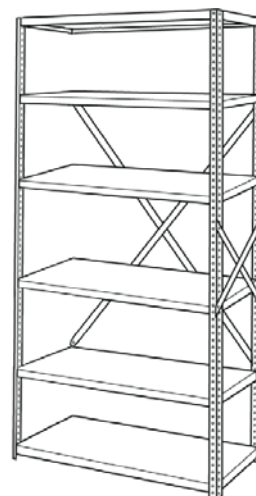

**6 SHELF  
ADD-ON KITS**

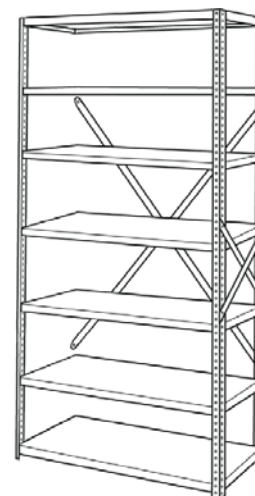

**7 SHELF  
ADD-ON KITS**

SHELF D" x W"	75"H				87"H				99"H			
	18 GAUGE		20 GAUGE		18 GAUGE		20 GAUGE		18 GAUGE		20 GAUGE	
	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT	MODEL NO.	SHIP WGT
<b>5 Shelf, 75"H Open Shelving Unit</b>				<b>5 Shelf, 87"H Open Shelving Unit</b>				<b>5 Shelf, 99"H Open Shelving Unit</b>				
12" x 36"	AD18G-75-1236-5	61 lbs	AD20G-75-1236-5	53 lbs	AD18G-87-1236-5	63 lbs	AD20G-87-1236-5	55 lbs	AD18G-99-1236-5	64 lbs	AD20G-99-1236-5	56 lbs
15" x 36"	AD18G-75-1536-5	73 lbs	AD20G-75-1536-5	56 lbs	AD18G-87-1536-5	75 lbs	AD20G-87-1536-5	58 lbs	AD18G-99-1536-5	76 lbs	AD20G-99-1536-5	59 lbs
18" x 36"	AD18G-75-1836-5	81 lbs	AD20G-75-1836-5	62 lbs	AD18G-87-1836-5	83 lbs	AD20G-87-1836-5	64 lbs	AD18G-99-1836-5	84 lbs	AD20G-99-1836-5	65 lbs
24" x 36"	AD18G-75-2436-5	101 lbs	AD20G-75-2436-5	78 lbs	AD18G-87-2436-5	103 lbs	AD20G-87-2436-5	80 lbs	AD18G-99-2436-5	104 lbs	AD20G-99-2436-5	81 lbs
30" x 36"	AD18G-75-3036-5	117 lbs	AD20G-75-3036-5	90 lbs	AD18G-87-3036-5	119 lbs	AD20G-87-3036-5	92 lbs	AD18G-99-3036-5	120 lbs	AD20G-99-3036-5	93 lbs
12" x 42"	AD18G-75-1242-5	73 lbs	AD20G-75-1242-5	61 lbs	AD18G-87-1242-5	75 lbs	AD20G-87-1242-5	64 lbs	AD18G-99-1242-5	76 lbs	AD20G-99-1242-5	65 lbs
15" x 42"	AD18G-75-1542-5	82 lbs	AD20G-75-1542-5	63 lbs	AD18G-87-1542-5	84 lbs	AD20G-87-1542-5	65 lbs	AD18G-99-1542-5	85 lbs	AD20G-99-1542-5	66 lbs
18" x 42"	AD18G-75-1842-5	91 lbs	AD20G-75-1842-5	70 lbs	AD18G-87-1842-5	93 lbs	AD20G-87-1842-5	71 lbs	AD18G-99-1842-5	94 lbs	AD20G-99-1842-5	72 lbs
24" x 42"	AD18G-75-2442-5	114 lbs	AD20G-75-2442-5	84 lbs	AD18G-87-2442-5	115 lbs	AD20G-87-2442-5	85 lbs	AD18G-99-2442-5	116 lbs	AD20G-99-2442-5	86 lbs
30" x 42"	AD18G-75-3042-5	132 lbs	AD20G-75-3042-5	94 lbs	AD18G-87-3042-5	134 lbs	AD20G-87-3042-5	97 lbs	AD18G-99-3042-5	135 lbs	AD20G-99-3042-5	97 lbs
12" x 48"	AD18G-75-1248-5	80 lbs	AD20G-75-1248-5	67 lbs	AD18G-87-1248-5	82 lbs	AD20G-87-1248-5	69 lbs	AD18G-99-1248-5	83 lbs	AD20G-99-1248-5	70 lbs
15" x 48"	AD18G-75-1548-5	90 lbs	AD20G-75-1548-5	70 lbs	AD18G-87-1548-5	91 lbs	AD20G-87-1548-5	70 lbs	AD18G-99-1548-5	92 lbs	AD20G-99-1548-5	72 lbs
18" x 48"	AD18G-75-1848-5	99 lbs	AD20G-75-1848-5	75 lbs	AD18G-87-1848-5	101 lbs	AD20G-87-1848-5	77 lbs	AD18G-99-1848-5	102 lbs	AD20G-99-1848-5	78 lbs
24" x 48"	AD18G-75-2448-5	125 lbs	AD20G-75-2448-5	94 lbs	AD18G-87-2448-5	127 lbs	AD20G-87-2448-5	95 lbs	AD18G-99-2448-5	128 lbs	AD20G-99-2448-5	96 lbs
30" x 48"	AD18G-75-3048-5	146 lbs	AD20G-75-3048-5	112 lbs	AD18G-87-3048-5	148 lbs	AD20G-87-3048-5	113 lbs	AD18G-99-3048-5	149 lbs	AD20G-99-3048-5	114 lbs
<b>6 Shelf, 75"H Open Shelving Unit</b>				<b>6 Shelf, 87"H Open Shelving Unit</b>				<b>6 Shelf, 99"H Open Shelving Unit</b>				
12" x 36"	AD18G-75-1236-6	69 lbs	AD20G-75-1236-6	60 lbs	AD18G-87-1236-6	71 lbs	AD20G-87-1236-6	62 lbs	AD18G-99-1236-6	72 lbs	AD20G-99-1236-6	63 lbs
15" x 36"	AD18G-75-1536-6	84 lbs	AD20G-75-1536-6	64 lbs	AD18G-87-1536-6	86 lbs	AD20G-87-1536-6	66 lbs	AD18G-99-1536-6	87 lbs	AD20G-99-1536-6	67 lbs
18" x 36"	AD18G-75-1836-6	93 lbs	AD20G-75-1836-6	69 lbs	AD18G-87-1836-6	96 lbs	AD20G-87-1836-6	72 lbs	AD18G-99-1836-6	97 lbs	AD20G-99-1836-6	73 lbs
24" x 36"	AD18G-75-2436-6	117 lbs	AD20G-75-2436-6	89 lbs	AD18G-87-2436-6	119 lbs	AD20G-87-2436-6	91 lbs	AD18G-99-2436-6	120 lbs	AD20G-99-2436-6	92 lbs
30" x 36"	AD18G-75-3036-6	136 lbs	AD20G-75-3036-6	104 lbs	AD18G-87-3036-6	138 lbs	AD20G-87-3036-6	106 lbs	AD18G-99-3036-6	139 lbs	AD20G-99-3036-6	107 lbs
12" x 42"	AD18G-75-1242-6	84 lbs	AD20G-75-1242-6	70 lbs	AD18G-87-1242-6	86 lbs	AD20G-87-1242-6	72 lbs	AD18G-99-1242-6	87 lbs	AD20G-99-1242-6	73 lbs
15" x 42"	AD18G-75-1542-6	94 lbs	AD20G-75-1542-6	72 lbs	AD18G-87-1542-6	96 lbs	AD20G-87-1542-6	73 lbs	AD18G-99-1542-6	97 lbs	AD20G-99-1542-6	74 lbs
18" x 42"	AD18G-75-1842-6	104 lbs	AD20G-75-1842-6	78 lbs	AD18G-87-1842-6	107 lbs	AD20G-87-1842-6	81 lbs	AD18G-99-1842-6	108 lbs	AD20G-99-1842-6	82 lbs
24" x 42"	AD18G-75-2442-6	132 lbs	AD20G-75-2442-6	96 lbs	AD18G-87-2442-6	134 lbs	AD20G-87-2442-6	98 lbs	AD18G-99-2442-6	135 lbs	AD20G-99-2442-6	99 lbs
30" x 42"	AD18G-75-3042-6	154 lbs	AD20G-75-3042-6	108 lbs	AD18G-87-3042-6	156 lbs	AD20G-87-3042-6	110 lbs	AD18G-99-3042-6	157 lbs	AD20G-99-3042-6	111 lbs
12" x 48"	AD18G-75-1248-6	92 lbs	AD20G-75-1248-6	76 lbs	AD18G-87-1248-6	94 lbs	AD20G-87-1248-6	78 lbs	AD18G-99-1248-6	95 lbs	AD20G-99-1248-6	79 lbs
15" x 48"	AD18G-75-1548-6	103 lbs	AD20G-75-1548-6	79 lbs	AD18G-87-1548-6	105 lbs	AD20G-87-1548-6	81 lbs	AD18G-99-1548-6	106 lbs	AD20G-99-1548-6	82 lbs
18" x 48"	AD18G-75-1848-6	115 lbs	AD20G-75-1848-6	87 lbs	AD18G-87-1848-6	117 lbs	AD20G-87-1848-6	88 lbs	AD18G-99-1848-6	118 lbs	AD20G-99-1848-6	89 lbs
24" x 48"	AD18G-75-2448-6	146 lbs	AD20G-75-2448-6	108 lbs	AD18G-87-2448-6	147 lbs	AD20G-87-2448-6	110 lbs	AD18G-99-2448-6	148 lbs	AD20G-99-2448-6	111 lbs
30" x 48"	AD18G-75-3048-6	171 lbs	AD20G-75-3048-6	129 lbs	AD18G-87-3048-6	173 lbs	AD20G-87-3048-6	131 lbs	AD18G-99-3048-6	174 lbs	AD20G-99-3048-6	132 lbs
<b>7 Shelf, 75"H Open Shelving Unit</b>				<b>7 Shelf, 87"H Open Shelving Unit</b>				<b>7 Shelf, 99"H Open Shelving Unit</b>				
12" x 36"	AD18G-75-1236-7	78 lbs	AD20G-75-1236-7	67 lbs	AD18G-87-1236-7	79 lbs	AD20G-87-1236-7	69 lbs	AD18G-99-1236-7	80 lbs	AD20G-99-1236-7	70 lbs
15" x 36"	AD18G-75-1536-7	95 lbs	AD20G-75-1536-7	71 lbs	AD18G-87-1536-7	97 lbs	AD20G-87-1536-7	73 lbs	AD18G-99-1536-7	98 lbs	AD20G-99-1536-7	74 lbs
18" x 36"	AD18G-75-1836-7	106 lbs	AD20G-75-1836-7	79 lbs	AD18G-87-1836-7	108 lbs	AD20G-87-1836-7	81 lbs	AD18G-99-1836-7	109 lbs	AD20G-99-1836-7	82 lbs
24" x 36"	AD18G-75-2436-7	133 lbs	AD20G-75-2436-7	102 lbs	AD18G-87-2436-7	135 lbs	AD20G-87-2436-7	102 lbs	AD18G-99-2436-7	135 lbs	AD20G-99-2436-7	103 lbs
30" x 36"	AD18G-75-3036-7	155 lbs	AD20G-75-3036-7	118 lbs	AD18G-87-3036-7	157 lbs	AD20G-87-3036-7	120 lbs	AD18G-99-3036-7	158 lbs	AD20G-99-3036-7	121 lbs
12" x 42"	AD18G-75-1242-7	95 lbs	AD20G-75-1242-7	79 lbs	AD18G-87-1242-7	97 lbs	AD20G-87-1242-7	81 lbs	AD18G-99-1242-7	98 lbs	AD20G-99-1242-7	82 lbs
15" x 42"	AD18G-75-1542-7	107 lbs	AD20G-75-1542-7	80 lbs	AD18G-87-1542-7	109 lbs	AD20G-87-1542-7	82 lbs	AD18G-99-1542-7	110 lbs	AD20G-99-1542-7	83 lbs
18" x 42"	AD18G-75-1842-7	119 lbs	AD20G-75-1842-7	89 lbs	AD18G-87-1842-7	121 lbs	AD20G-87-1842-7	91 lbs	AD18G-99-1842-7	122 lbs	AD20G-99-1842-7	92 lbs
24" x 42"	AD18G-75-2442-7	150 lbs	AD20G-75-2442-7	108 lbs	AD18G-87-2442-7	152 lbs	AD20G-87-2442-7	110 lbs	AD18G-99-2442-7	153 lbs	AD20G-99-2442-7	111 lbs
30" x 42"	AD18G-75-3042-7	176 lbs	AD20G-75-3042-7	123 lbs	AD18G-87-3042-7	178 lbs	AD20G-87-3042-7	125 lbs	AD18G-99-3042-7	179 lbs	AD20G-99-3042-7	126 lbs
12" x 48"	AD18G-75-1248-7	104 lbs	AD20G-75-1248-7	86 lbs	AD18G-87-1248-7	106 lbs	AD20G-87-1248-7	88 lbs	AD18G-99-1248-7	107 lbs	AD20G-99-1248-7	89 lbs
15" x 48"	AD18G-75-1548-7	117 lbs	AD20G-75-1548-7	89 lbs	AD18G-87-1548-7	119 lbs	AD20G-87-1548-7	91 lbs	AD18G-99-1548-7	120 lbs	AD20G-99-1548-7	92 lbs
18" x 48"	AD18G-75-1848-7	126 lbs	AD20G-75-1848-7	98 lbs	AD18G-87-1848-7	133 lbs	AD20G-87-1848-7	100 lbs	AD18G-99-1848-7	134 lbs	AD20G-99-1848-7	101 lbs
24" x 48"	AD18G-75-2448-7	166 lbs	AD20G-75-2448-7	122 lbs	AD18G-87-2448-7	168 lbs	AD20G-87-2448-7	124 lbs	AD18G-99-2448-7	169 lbs	AD20G-99-2448-7	125 lbs
30" x 48"	AD18G-75-3048-7	196 lbs	AD20G-75-3048-7	147 lbs	AD18G-87-3048-7	197 lbs	AD20G-87-3048-7	149 lbs	AD18G-99-3048-7	198 lbs	AD20G-99-3048-7	150 lbs